



Datenblatt - Fiche technique - Data sheet

11.09.4389




ROLINE Fiber-Kabel Toslink ST / ST, 10m


ROLINE Câble Toslink M/M, 10m

ROLINE Fiber Cable Toslink M - M, 10 m

1. DIMENSION

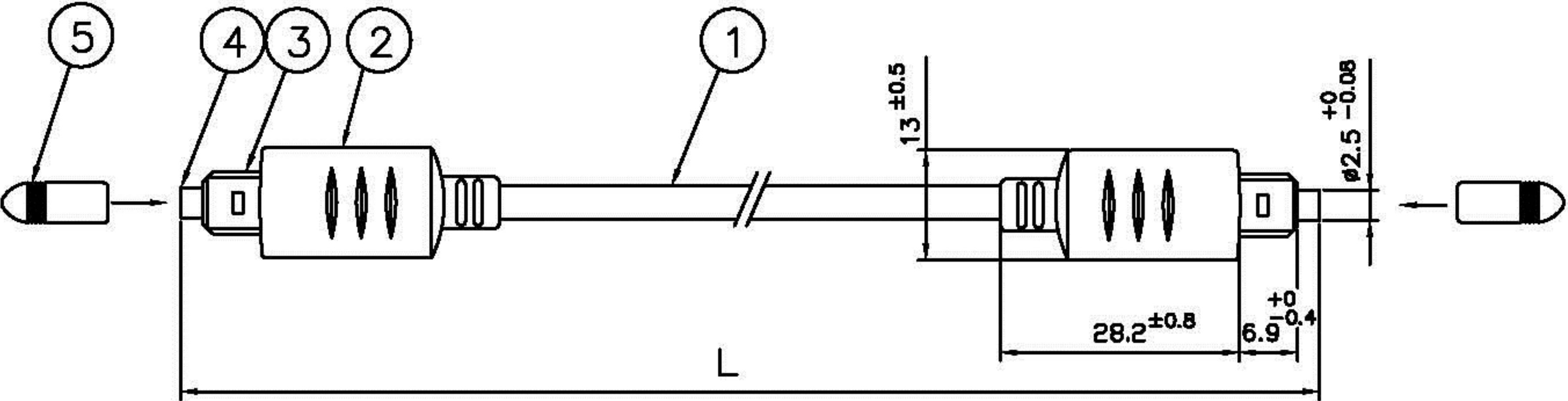

CORD SPEC.

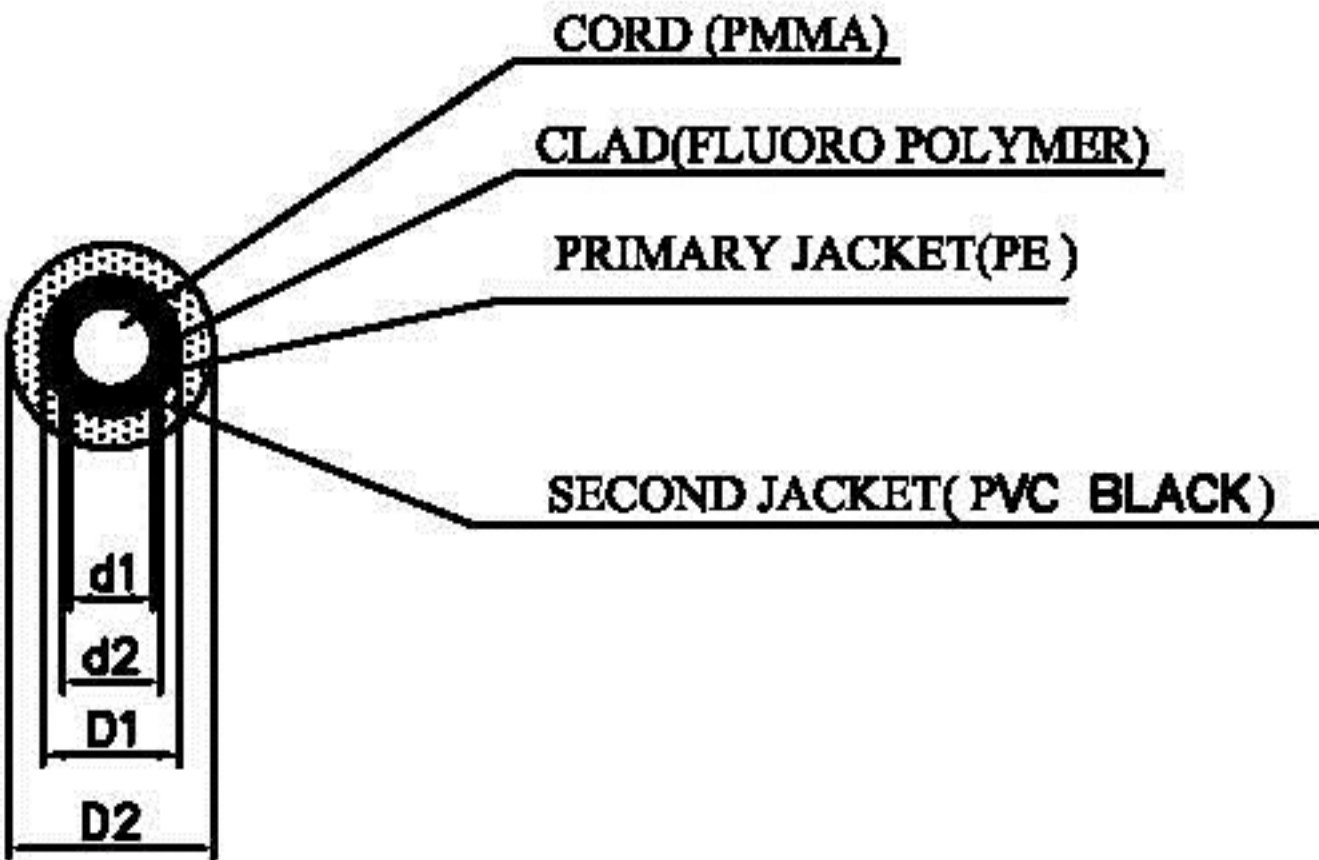

- NOTE:
- 1.100 % TESTING.
 - 2.TRANSMISSION LOSS 4.0 dB (L=10M) OR LESS
 - 3.MATING FORCE :39.2N(4.0Kgf) OR LESS
 - 4.UMMATING FORCE :5.9N(0.6Kgf) ~39.2N (4.0Kgf)
 - 5.ALL DIMENSION ARE IN MILLIMETERS.
 - 6.ALL MATERIAL ARE RoHS COMPLIANT.

d1... CORE DIAMETER	φ 0.98mm
d2... CLAD DIAMETER	φ 1.0mm
D1... PRIMARY JACKET DIAMETER	φ 2.2±0.07mm
D2... SECOND JACKET DIAMETER	φ 4.0±0.2mm

RoHS COMPLIANT

PART LISTS

NO	DESCRIPTION	MATERIAL	Q'TY	COLOR.FINISHED
1	OPTICAL FIBER CABLE	PVC	1	PANTONE BLACK C
2	OPT PLUG CAP	PVC	2	PANTONE BLACK C
3	TOSLINK OPT PLUG	PBT+G30%	1	PANTONE BLACK C
4	CENTER PIN	BRASS	1	24K GOLD PLATED
5	PROTECTIVE CAP	PVC	2	TRANSPARENT

REV : 1

△					POWERS		Rotronic Co., Ltd
△					COLOR		
△					WORKING		
△					PROCESS		
△					MATERIAL		
MARK	REVISION			DATE	SIGN	APPO	PART NO
APPROVED BY	CHECKED BY	DESIGNED BY	DRAWN BY				11.09.4385
		SHEU	SHEU				11.09.4389
		2012-06-15	2012-06-15				DESCRIPTION.
							ROLINE Toslink Cable M-M, 5.0m & 10.0m
							DRAWN NO.
							SHEET
							1/1