



Datenblatt - Fiche technique - Data sheet



21.15.2601



ROLINE Patchkabel Kat.6 S/FTP (PiMF), Component Level, LSOH, grau, 1,0 m

Cordon ROLINE S/FTP(PiMF) Cat.6, LSOH, Component Level, gris, 1,0 m

ROLINE S/FTP Patch Cord Cat.6 Component Level, LSOH, grey, 1.0 m

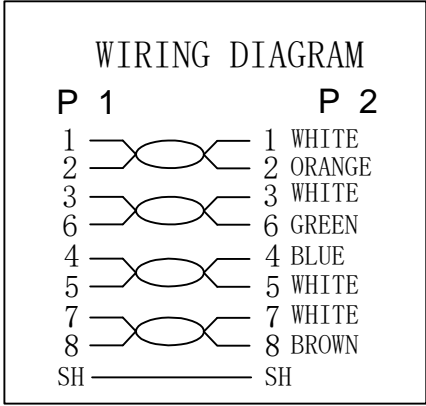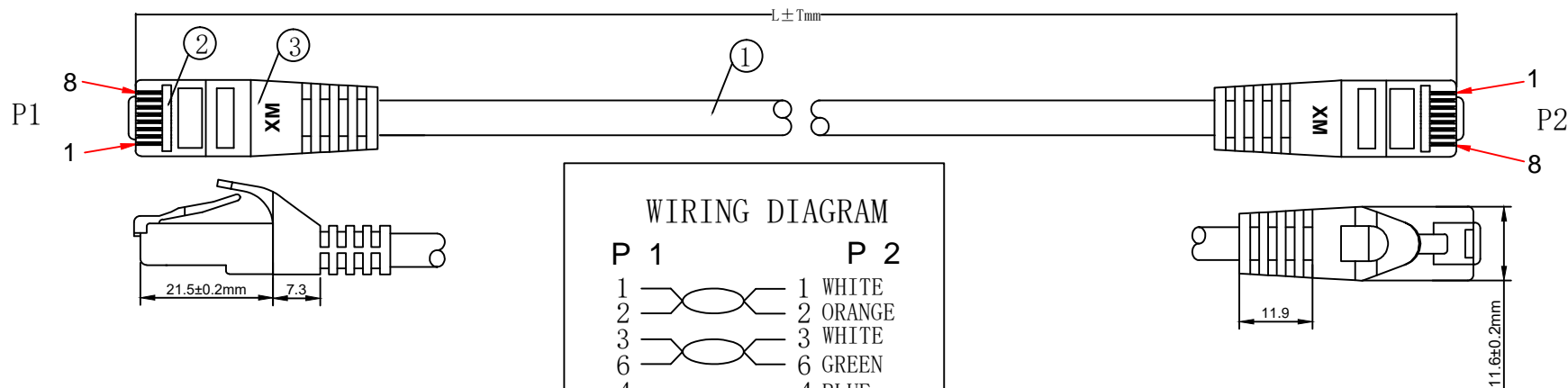

1. ELECTRICAL TEST:

- (1). 100% OPEN SHORT & MISS WIRE TEST;
- (2). INSULATION RESISTANCE:DC 250V 20M OHM MIN;
- (3). CONTACTOR RESISTANCE:30 OHM MAX

2. PRINTING:GHMT® roline CAT.6 S/FTP COMPONENT PATCH CORD LSZH 250MHz ISO/IEC 11801 & EN 50173-1 & ANSI/TIA-568-C.2

3. 100% Component Patch cord Test PASS

4. Minimum bending radius:60mm

MATERIAL LIST

⑥	LABEL	NO DRY GLUE LABEL	1PCS	
⑤	MINI TIE	PE MINI TIE (POSSESS METAL)	2PCS	
④	POLYETHYLENE BAG	POLYETHYLENE BAG	1PCS	
③	OVER MOLD	88A PVC Grey	2PCS	
②	CONNECTOR	RJ45 8P8C'S SHIELDED PIN GOLD PLATED 3u", SHELL PLATED NICKEL Transparent RED	2PCS	
①	CABLE	S/FTP CAT.6 26AWG (BC*1P+AL-FOIL)*4P+BRAID CABLE JACKET LSOH OD=6.2 ± 0.2MM	1PCS	
NO.	PARTS NAME	SPECIFICATION STANDARD	QT' Y	REMARK

ARVIN	ALVAN	CHANGE COLOR GREY	2016-11-28	A1
		NEW	2016-10-20	A
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.

COLOUR:GRAY (RAL 7035)					
ITEM NO.	LENGTH (L)	TOLERANCE (T)			
21. 15. 2951	300mm	± 10mm			
21. 15. 2600	500mm	± 15mm			
21. 15. 2601	1000mm	± 30mm			
21. 15. 2604	1500mm	± 45mm			
21. 15. 2602	2000mm	± 60mm			
21. 15. 2603	3000mm	± 90mm			
21. 15. 2605	5000mm	± 150mm			
21. 15. 2606	7500mm	± 210mm			
21. 15. 2607	10000mm	± 300mm			
21. 15. 2608	15000mm	± 450mm			
21. 15. 2609	20000mm	± 600mm			
ITEM NO.	21. 15. 2951	21. 15. 2600	21. 15. 2601	21. 15. 2602	21. 15. 2603
21. 15. 2604	21. 15. 2605	21. 15. 2606	21. 15. 2607	21. 15. 2608	21. 15. 2609
DESC.	ROLINE S/FTP PatchCord CAT. 6, LSOH, Comp. Level, grey				

SECOMP