



Datenblatt - Fiche technique - Data sheet


**21.15.2709**



ROLINE Patchkabel Kat.6A UTP, Component Level, LSOH, grau, 20 m

Cordon ROLINE UTP Cat.6A / 10 Gigabit, Component Level, LSOH, gris, 20 m

ROLINE UTP Patch Cord Cat.6A, Component Level, LSOH, grey, 20.0 m

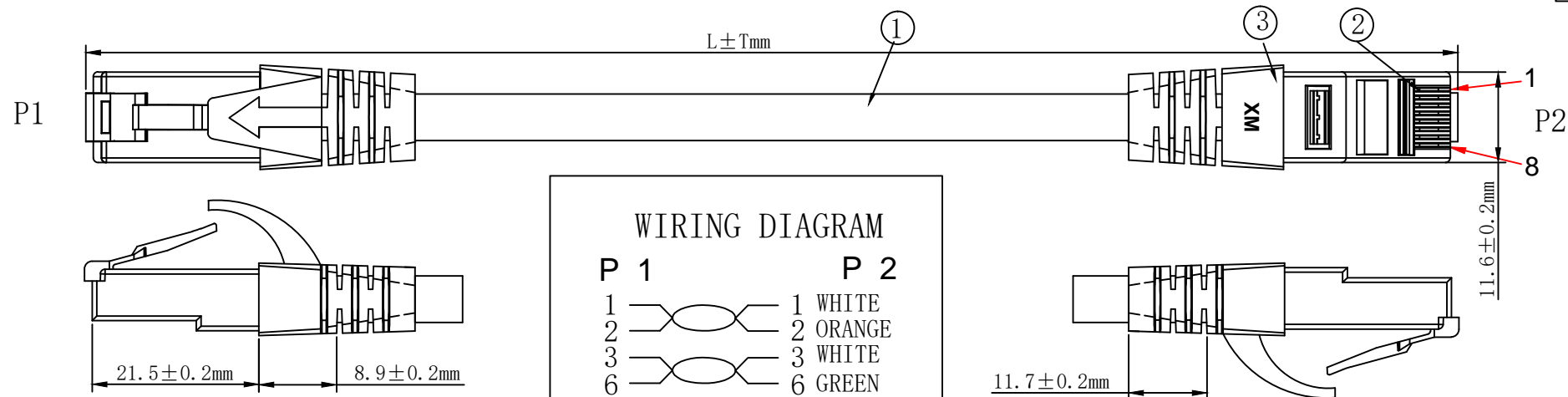

**1. ELECTRICAL TEST:**

- (1).100% OPEN SHORT & MISS WIRE TEST;
- (2).INSULATION RESISTANCE:DC 250V 20M OHM MIN;
- (3).CONTACTOR RESISTANCE:30 OHM MAX

**2.PRINTING:GHMT® roline CAT.6A U/UTP COMPONENT PATCH CORD LSZH 500MHZ ISO/IEC**

11801 & EN 50173-1 & ANSI/TIA-568-C.2

3.100% Component Patch cord Test PASS

4.Minimum bending radius:60mm

**MATERIAL LIST**

⑥	LABEL	NO DRY GLUE LABEL	1PCS	
⑤	MINI TIE	PE MINI TIE(POSSESS METAL)	2PCS	
④	POLYETHYLENE BAG	POLYETHYLENE BAG	1PCS	
③	OVER MOLD	88A PVC Grey	2PCS	
②	CONNECTOR	RJ45 8P8C'S UNSHIELDED PIN GOLD PLATED 3u", Transparent Blue	2PCS	
①	CABLE	S/FTP CAT.6A 26AWG (BC*1P+AL-FOIL)*4P+BRAID CABLE JACKET LSOH OD=6.2±0.2MM	1PCS	
NO.	PARTS NAME	SPECIFICATION STANDARD	QT' Y	REMARK

COLOUR:GRAY (RAL 7035)		
ITEM NO.	LENGTH (L)	TOLERANCE (T)
21.15.2981	300mm	±10mm
21.15.2700	500mm	±15mm
21.15.2701	1000mm	±30mm
21.15.2704	1500mm	±45mm
21.15.2702	2000mm	±60mm
21.15.2703	3000mm	±90mm
21.15.2705	5000mm	±150mm
21.15.2706	7500mm	±210mm
21.15.2707	10000mm	±300mm
21.15.2708	15000mm	±450mm
21.15.2709	20000mm	±600mm

ITEM NO.	21.15.2981	21.15.2700	21.15.2701	21.15.2702	21.15.2703
21.15.2704	21.15.2705	21.15.2706	21.15.2707	21.15.2708	21.15.2709
DESC.	ROLINE U/UTP PatchCord CAT.6A, LSOH, Comp.Level1, grey				

ARVIN	ALVAN	CHANGE COLOR GREY	2016-11-28	A1	
		NEW	2016-09-13	A	
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.	

