


**Vacuum refrigerator pygmy lamp
230V 15W S26 clear bulb 1000h SES cap**

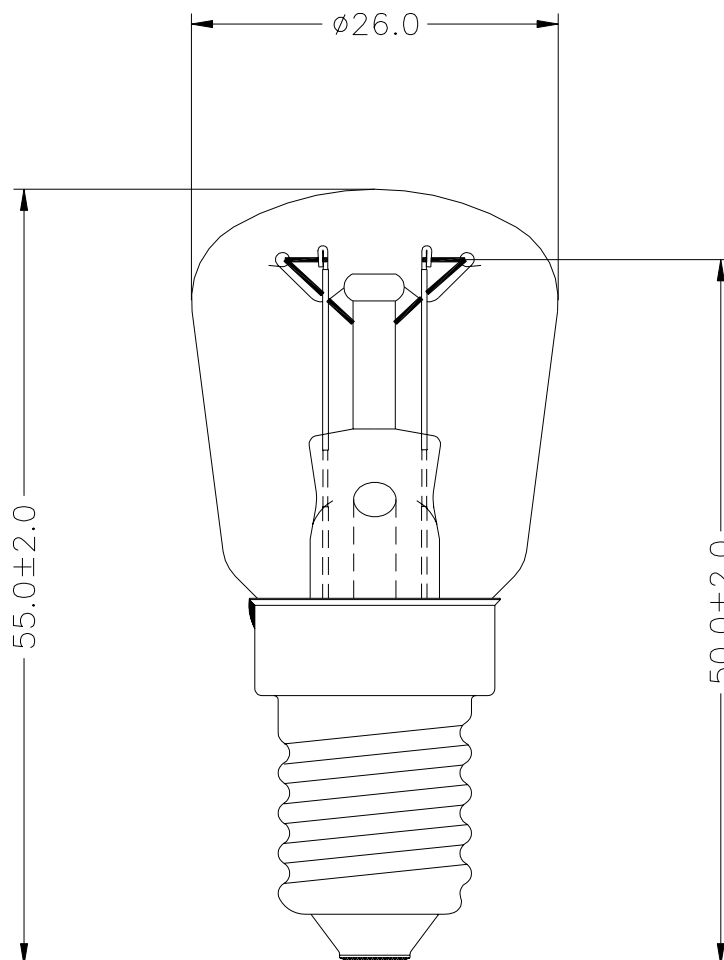

Design:

Bulb: S26 clear
Cap: E14/25x17 brass
Filling gas: - (vacuum)
Filament: CC-9 (without tails)
Number of supports: 3
Fuse: -

Electrical and photometric characteristics:

Rated values:	240 V	Limits:
	15 W	max. 16.1 W
	85 lm	min. 79 lm
	1000 h	min. 700 h
	80% lumen maintenance	

General description:

Burning position: Universal
External specifications: IEC 60061-1
Tested according to: IEC 60064, IEC 60432