



ES CAPS
Polyolefin, Dual-Wall
Semi-Rigid, Heat - Shrinkable

As Supplied

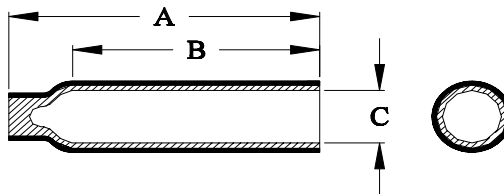

After Unrestricted Recovery

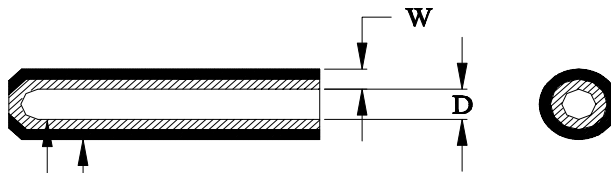

Outer Jacket
Heat shrinkable semirigid, irradiated,
modified polyolefin

Inner Wall
Adhesive

Color: Black or Clear
Temperature rating: -40°C to 105°C
Material: Per RW-3006

Specification Control Drawing

tyco <i>Electronics</i>	Tyco Electronics Corporation 300 Constitutional Drive Menlo Park, CA 94025 USA	Raychem	Title: ES CAPS Polyolefin, Dual-Wall Semi-Rigid, Heat - Shrinkable		
	Tyco Electronics reserves the right to amend this drawing at any time. Users should evaluate the suitability of the product for their application	Document No : ES CAPS			
Cage Code: 06090	Scale: None	Size: A	Rev. Date: January 14, 2004	Rev.: B	Sheet: 1 of 2

Print Date: 19-Jan-04 **If this document is printed it becomes uncontrolled. Check for the latest revision.**

Table 1
Dimensions (mm /In)

Part No.	A ±3.81/.150	B Min.	C Min.	D Max.	W Min.	Adhesive Wall min.
ES-CAP-No.1-30mm	30/1.18	16.78/660	5.7/225	1.3/050	1.2/047	.56/022
ES-CAP-No.1-35mm	35/1.38	21.18/833	5.7/225	1.3/050	1.2/047	.56/022
ES-CAP-No.1-40mm	40/1.575	25.58/1.005	5.7/225	1.3/050	1.2/047	.56/022
ES-CAP-No.1-45mm	45/1.772	28.45/1.120	5.7/225	1.3/050	1.2/047	.56/022
ES-CAP-No.1-50mm	50/1.97	36.68/1.445	5.7/225	1.3/050	1.2/047	.56/022
ES-CAP-No.2-30mm	30/1.18	16.78/660	7.4/293	1.7/065	1.52/060	.76/030
ES-CAP-No.2-35mm	35/1.38	21.18/833	7.4/293	1.7/065	1.52/060	.76/030
ES-CAP-No.2-40mm	40/1.575	25.58/1.005	7.4/293	1.7/065	1.52/060	.76/030
ES-CAP-No.2-50mm	50/1.97	36.68/1.445	7.4/293	1.7/065	1.52/060	.76/030
ES-CAP-No.3-30mm	30/1.18	16.78/660	10.8/427	2.41/095	1.91/075	1.02/040
ES-CAP-No.3-35mm	35/1.38	21.18/833	10.8/427	2.41/095	1.91/075	1.02/040
ES-CAP-No.3-40mm	40/1.575	22.48/920	10.8/427	2.41/095	1.91/075	1.02/040
ES-CAP-No.3-50mm	50/1.97	33.58/1.320	10.8/427	2.41/095	1.91/075	1.02/040