 



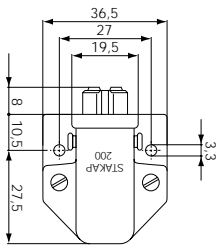

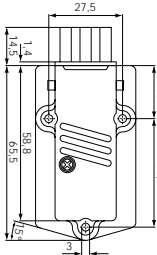

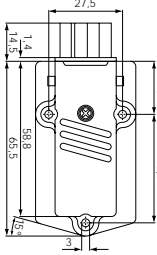

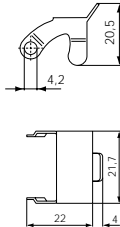

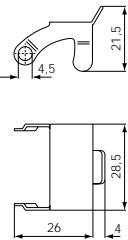


# Connectors for mains connection



## ST-series

HiPower

Type		Number of poles	Description	Order no.
 <p>STAKAP 200</p>		2 + PE	Surface-mounted socket with cast baseplate and coding slot, additional sealing for IP 54 necessary Operating current: 16 A AC / 10 A DC	932 045-106
 <p>STAKAP 3 N</p>		3 + PE	Surface-mounted socket Operating current: 16 A AC / 10 A DC	932 513-106
 <p>STAKAP 5</p>		5 + PE	Surface-mounted socket, not assembled with added contacts Operating current: 6 A AC / 10 A DC	932 511-106
 <p>STASI 2</p>		—	Safety brackets for 2 + PE - versions	732 044-000
 <p>STASI 3</p>		—	Safety bracket for 3 + PE and 5 + PE - versions	732 045-001