

709-5661  
709-5673

# Use/Plunger Cans & Bench Cans

Justrite production containers help you handle flammable liquids safely and economically. You can cut lost time in washing parts, applying solvents, moistening cleaning rags and many other production line operations involving flammable liquids. Best results are achieved by job-matching containers to the specific function which will improve operator output.

Plunger Cans help you quickly, easily moisten cleaning cloths or swabs. Pushing down fills upper pan for moistening. Surplus liquid drains safely back into reservoir. Pump assembly is brass. The perforated pan screen serves as a flame arrester. Top rims have molded edge protectors for smooth, trouble-free moistening. Available in terne plate or high-density polyethylene construction.




Dispenser Cans easily permit one-hand dispensing of liquids directly on work. Brass dispenser valves are leakproof and self-closing to minimize spills and control excess. Brass valves are FM-approved and recommended for flammables only. Rugged polyethylene body.

Chemical Dispensers offer simple "one-touch" operation and are ideal anywhere processes require small, controlled amounts of liquids. Flip open cap and lightly press down with cotton swab or brush. Liquid pumps up and won't drain back into the container to prevent contamination of contents. All polyethylene body with stainless steel pump seals all contents and minimizes evaporation loss while protecting against the escape of toxic and/or flammable vapors. The pump carries a lifetime guarantee.

Bench Cans provide an easy means of cleaning small parts in solvents. Simply place work on spring-loaded, perforated dasher plate, press down and agitate, then release to return dasher to drain position. Plated steel dasher is an effective flame arrester. Hinged cover minimizes evaporation losses. Protected rim reduces possibility of hand injury. Optional parts basket available.

## Plunger Cans

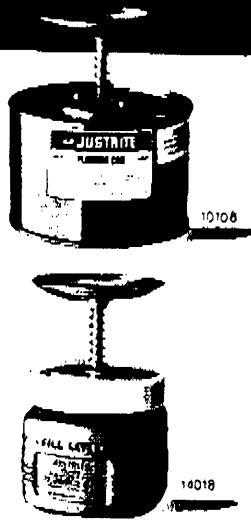


Capacity	Description	Approval Listing	Model No.
1 pint	Terne plate w/brass pump assembly; 4 1/2" OD x 6" H, dasher 2 1/4" dia.	FM	10008
1 quart	Terne plate w/brass pump assembly; 7 1/2" OD x 6 1/2" H, dasher 5" dia.	FM	10108
2 pint	Terne plate w/brass pump assembly; 4 1/2" OD x 8 1/2" H, dasher 5" dia.	FM	10143
1/2 gallon	Terne plate w/brass pump assembly; 7 1/2" OD x 8" H, dasher 5" dia.	FM	10208
1 gallon	Terne plate w/brass pump assembly; 7 1/2" OD x 11" H, dasher 5" dia.	FM	10308
1 quart	Nonmetallic w/brass pump assembly; 5 1/2" x 5 1/2" x 9" H, dasher 5" dia.	FM	14018

## Dispenser Cans




Capacity	Description	Approval Listing	Model No.
4 ounce	Nonmetallic w/self-closing brass valve, 2 1/4" OD x 5 1/2" H		14002
1/2 pint	Nonmetallic w/self-closing brass valve, 3 1/4" OD x 5 1/2" H	FM	14004
1 quart	Nonmetallic w/self-closing brass valve, 4" OD x 10 1/2" H	FM	14010

## Chemical Dispensers

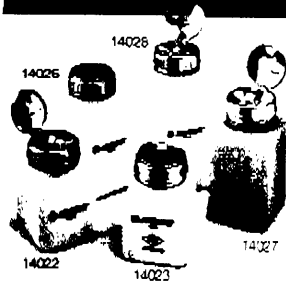

Capacity	Description	Approval Listing	Model No.
4 ounce	Nonmetallic w/stainless steel pump, 2" x 2" x 3 1/4" (packed 12/carton)		14022
6 ounce	Nonmetallic w/stainless steel pump, 2 1/4" x 2 1/4" x 4 1/4" (packed 12/carton)		14026
8 ounce	Nonmetallic w/stainless steel pump, 2 1/4" x 2 1/4" x 5" (packed 12/carton)		14028
4 ounce	Nonmetallic w/stainless steel pump, 2" x 2" x 3 1/4" (packed 12/carton)	FM	14023
6 ounce	Static dissipative plastic w/stainless steel pump, 2 1/4" x 2 1/4" x 4 1/4" (packed 12/carton)		14027

## Bench Cans

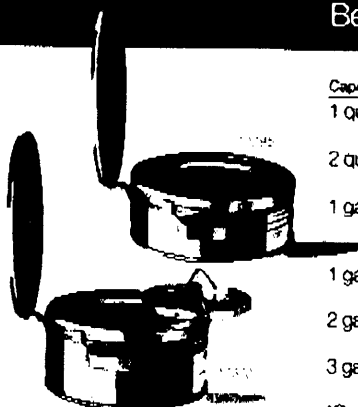

Capacity	Description	Approval Listing	Model No.
1 quart	Terne plate steel, 4 1/4" OD x 5 1/2" H, plated steel dasher/flame arrester 4 1/2" dia.	FM	10175
2 quart	Terne plate steel, 9 1/4" OD x 3 1/2" H, plated steel dasher/flame arrester 7 1/2" dia.	FM	10295*
1 gallon	Terne plate steel, 9 1/4" OD x 4 1/2" H, w/1/2" H x 6 1/4" dia. parts basket; plated steel dasher/flame arrester 7 1/2" dia.	FM	10370
1 gallon	Terne plate steel, 9 1/4" OD x 4 1/2" H, plated steel dasher/flame arrester 7 1/2" dia.	FM	10375*
2 gallon	Terne plate steel, 11 1/2" OD x 5 1/4" H, plated steel dasher/flame arrester 9 1/4" dia.	FM	10575
3 gallon	Terne plate steel, 13 1/2" OD x 6" H, plated steel dasher/flame arrester 12 1/4" dia.	FM	10775

\*Optional parts basket 11171.

**Convenient carrying handle.** When upright, stabilizes for carrying ease and minimal splash-over.

**Poly rim protector.** Eliminates potential cuts and scratches that often occur on unprotected parts cleaning equipment.

**Flash arresting protection.** Perforated metal dasher plate reliably dissipates heat to stop flashback ignition.

**Smooth pumping action.** Brass pump assembly resists troublesome chemicals, prevents corrosion that can cause hang-ups. Terne plate and polyethylene models are available.

**Easy maintenance.** Simple to assemble and dismantle for routine cleaning during solvent exchange.

**Flash arresting protection.** Perforated metal dasher plate reliably dissipates heat to stop flashback ignition.

**Optional parts basket.**

**Easy maintenance.** Simple to assemble and dismantle for routine cleaning during solvent change.

**Flash arresting protection.** Perforated metal tray reliably dissipates heat to stop flashback ignition.

**Smooth, safe operation.** Spring action provides easy up/down operation for parts immersion and cleaning.

