

309-9829  
**GOLIATH**<sup>®</sup>  
 BASIC 55

309-9799  
**GOLIATH**<sup>®</sup>  
 EXTENSION 55



### NEW PROFESSIONAL WORKLAMP - ALSO WITH SOCKET

The Goliath 55 ensures a good and safe worklight and provides a soft and even light on a large surface. The lamp is therefore suitable wherever a good worklight is required - irrespective of the tasks in industries, at construction sites, in workshops or in similar places. The Goliath is designed so that it can be placed in various angles, or be suspended so that it provides light exactly at the spot where light is needed.

The Goliath 55 Extension is equipped with a socket. The socket makes working a little easier - when the light has been mounted, a socket is available close by, either for more Goliath 55 lamps or for hand tools.

The Goliath 55 is made of shockproof materials, and is equipped with a shockabsorbent rubber surface which at the same time ensures a high degree of sealing. This means that the lamp has a long durability, and it makes use in both wet and dusty surroundings possible.

The Goliath 55 is equipped with an environmentally friendly 55 watt low-energy tube. This means that the lamp never gets hotter than handwarm. The tube has a life of 8,000 hours, which corresponds to 5 to 6 years' normal use.

### TECHNICAL SPECIFICATIONS

	BASIC	EXT.
Degree of protection:	IP65	IP54
Low-energy tube:	55W	55W
Light output (lumen):	4000	4000
Life of tube (hours):	8000	8000
Double insulation:	YES	YES
Socket:	NO	YES
Weight (kg):	3,7	4,1

Dimensions (cm): 36 x 30 x 15,5

#### Goliath 55 Basic

 

5 m oilproof H07RN-F 2 x 1,0 mm<sup>2</sup>

#### Goliath 55 Extension

5 m oilproof H07RN-F 3 x 1,5 mm<sup>2</sup>

Produced in Denmark  
 Design: Landerholm & Lund

**GOLIATH**<sup>®</sup>  
 EXTENSION 55

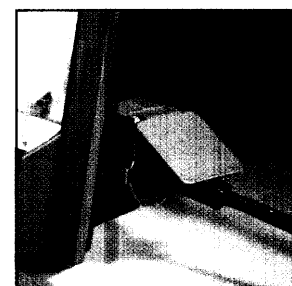

## SALES ARGUMENTS

- ◆ Powerful but comfortable worklight
- ◆ Many possibilities of adjustment - can stand, lay or hang
- ◆ Shockproof material - resists knocks and shocks also during use
- ◆ Low-energy tube of 55W with a life of approx. 8,000 hours
- ◆ Does not get hot

## ORDER NOS.

Order No.	Description	EAN-code
820930	Goliath 55 Basic	5702128209307
820910	Goliath 5 Basic with UK plug	5702128209109
820931	Goliath 55 Extension	5702128209314
820911	Goliath 55 Extension with UK plug	5702128209116

## SIZE OF PACKAGING

Product	Pcs. per pallet	Height of pallet (cm)
Goliath 55 Basic	102	240
Goliath 55 Extension	102	240

 

## ACCESSORIES

- ◆ Foldable multi stand with 4 legs for mounting of the Goliath 55 to a height of up to 2.5 meters
- ◆ Wall bracket for Goliath 55
- ◆ Goliath Booster 12V/230V, 140W

## MATERIAL FOR ADVERTISING

JO-EL offers assistance for local advertising in form of photos and logo material. Please contact us for further information.

## SHOP MATERIAL

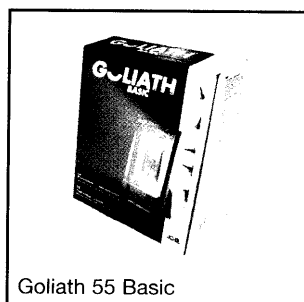

**GOLIATH**<sup>®</sup>  
**PROFESSIONAL  
WORKLIGHT**  
by JO-EL

**JO-EL**<sup>®</sup>