

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0451330410](#)
Status: **Active**
Overview: [Ultra-Fit Power Connectors](#)
Description: Ultra-Fit™ to Ultra-Fit™ Off-the-Shelf (OTS) Cable Assembly, Dual Row, 1.0m Length, 4 Circuits, Black

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	45133
Application	Power, Wire-to-Board
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Ultra-Fit-to-Ultra-Fit
Overview	Ultra-Fit Power Connectors
Product Literature Order No	987651-6143
Product Name	Ultra-Fit OTS
UPC	889056738675

Physical

Cable Length	1.0m
Circuits (Loaded)	4
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	High Conductivity Copper
Material - Plating Mating	Tin over Nickel
Material - Plating Termination	Tin over Nickel
Material - Resin	Nylon
Net Weight	60.300/g
Packaging Type	Bag
Pitch - Mating Interface	3.50mm
Plating min - Mating	1.524µm
Plating min - Termination	1.524µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	2.35mm
Wire Size AWG	16
Wire/Cable Type	UL 1061


Electrical

Current - Maximum per Contact	12.0A
Voltage - Maximum	300V

Material Info

Reference - Drawing Numbers

Sales Drawing	2012341007-000
---------------	----------------

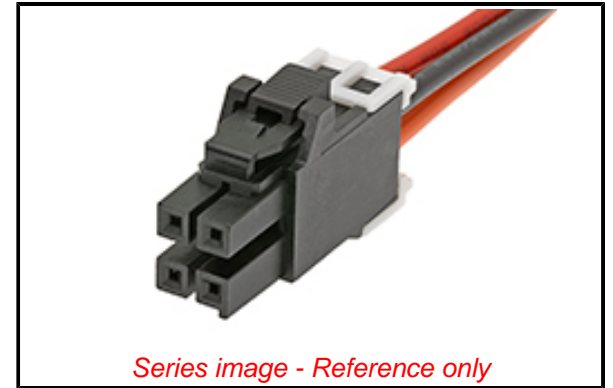

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant*

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

CUST_NOTE	*Product contains part(s) with customer managed
CUST_NOTE1	EHS data. These part(s) are excluded from product compliance status evaluation.
CUST_NOTE2	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[45133 Series](#)

Mates With

Ultra-Fit™ Right Angle Header [172316](#)

Ultra-Fit™ Vertical Header [172298](#) ,
[172299](#)