



Quality Products. Service Excellence.

Type 4 Mild Steel Wallmount Enclosure w/ Window *Eclipse Series*

Hinge Door with Quarter Turn



Application

- Designed to enclose electrical and/or electronic equipment in wallmount applications where viewing of component operation is necessary while maintaining protection ratings.
- Impressive styling features like hidden hinges, attractive latching systems make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

Standards

- UL 508A Type 3R, 4 and 12
- CSA Type 3R, 4 and 12
- Complies with
 - NEMA 3R, 4 and 12
 - IEC 60529, IP66

Construction

- Formed 14 or 16 gauge steel.
- Full view UV resistant polycarbonate window allow maximum viewing area of inner panel.
- Smooth, continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity - designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Door latches feature the added safety of quarter turn slot requiring use of tool for opening
- Doors may be easily removed for modifications and are interchangeable.
- Seamless poured-in place gasket.
- Collar studs provided for mounting inner panel.
- Includes hardware kit with panel mounting nuts and sealing washers for wall mounting holes.
- Bonding stud provided on door and grounding stud installed in enclosure.
- Hinges are constructed from 304 stainless steel.
- Hinge pins are stainless steel.
- Quarter turn latches are zinc diecast with black epoxy finish.


Finish

- Cover and enclosure are phosphatized and finished with a recoatable powder inside and out with choice of ANSI 61 smooth Gray (GY) or RAL7035 textured light gray (LG).

Accessories

- Cooling Products
- Ventilation
- DIN Rail Mounting Kit
- Drip Shield Kit
- Gland Plates
- Blowers and Fans
- DIN Rails
- Door Stop Kit
- Filtered Fans
- Heaters

- Handles
- Literature Pocket
- Mounting Foot Kit
- Swing Frame
- Rear Hole Plugs
- Quarter Turn Assemblies
- Type 4 Hardware Kits
- Padlock Adaptor
- Inner Panels
- Quarter Turn Inserts and Keys
- Swing Panel
- Eclipse Rack Panel
- Replacement Hinge Pins
- Temperature Controls
- Touch-Up Spray Paint
- Ground Wire Kits

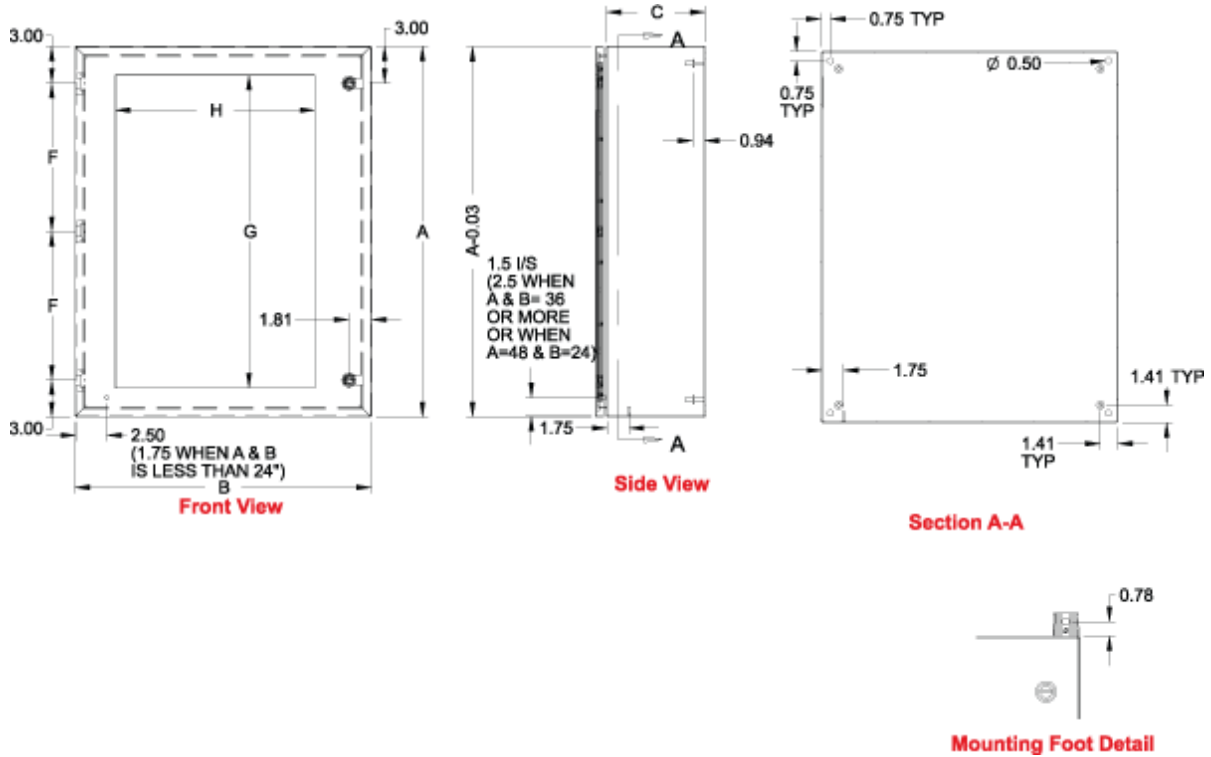

Part No. (ANSI 61 Gray)	Part No. (RAL7035 Light Gray)	Overall Dimensions			Door/Body Gauge	Latch ¹ Qty	Hinge Qty	Viewing Area			Optional Panel Part No.	Inner Panel Dimensions	
		A	B	C				F	G	H		D	E
EN4SD16126WGY	EN4SD16126WLG	16.00	12.00	6.00	16	1	2	10.00	11.33	6.71	EP1612	14.20	10.20
EN4SD20166WGY	EN4SD20166WLG	20.00	16.00	6.00	16	1	2	14.00	15.33	10.71	EP2016	18.20	14.20
EN4SD20206WGY	EN4SD20206WLG	20.00	20.00	6.00	16	1	2	14.00	15.33	14.71	EP2020	18.20	18.20
EN4SD24206WGY	EN4SD24206WLG	24.00	20.00	6.00	16	1	2	18.00	19.33	14.71	EP2420	22.20	18.20
EN4SD24246WGY	EN4SD24246WLG	24.00	24.00	6.00	14	2	2	18.00	19.33	16.15	EP2424	22.20	22.20
EN4SD16128WGY	EN4SD16128WLG	16.00	12.00	8.00	16	1	2	10.00	11.33	6.71	EP1612	14.20	10.20
EN4SD20168WGY	EN4SD20168WLG	20.00	16.00	8.00	16	1	2	14.00	15.33	10.71	EP2016	18.20	14.20
EN4SD20208WGY	EN4SD20208WLG	20.00	20.00	8.00	16	1	2	14.00	15.33	14.71	EP2020	18.20	18.20
EN4SD24208WGY	EN4SD24208WLG	24.00	20.00	8.00	16	1	2	18.00	19.33	14.71	EP2420	22.20	18.20
EN4SD24248WGY	EN4SD24248WLG	24.00	24.00	8.00	14	2	2	18.00	19.33	16.15	EP2424	22.20	22.20
EN4SD30248WGY	EN4SD30248WLG	30.00	24.00	8.00	14	2	3	12.00	25.33	16.15	EP3024	28.20	22.20
EN4SD202012WGY	EN4SD202012WLG	20.00	20.00	12.00	16	1	2	18.00	15.33	14.71	EP2020	18.20	18.20
EN4SD242012WGY	EN4SD242012WLG	24.00	20.00	12.00	16	1	2	18.00	19.33	14.71	EP2420	22.20	18.20
EN4SD242412WGY	EN4SD242412WLG	24.00	24.00	12.00	14	2	2	18.00	19.33	16.15	EP2424	22.20	22.20
EN4SD302412WGY	EN4SD302412WLG	30.00	24.00	12.00	14	2	3	12.00	25.33	16.15	EP3024	28.20	22.20
EN4SD242416WGY	EN4SD242416WLG	24.00	24.00	16.00	14	2	2	18.00	19.33	16.15	EP2424	22.20	22.20
EN4SD242420WGY	EN4SD242420WLG	24.00	24.00	20.00	14	2	2	18.00	19.33	16.15	EP2424	22.20	22.20
EN4SD302420WGY	EN4SD302420WLG	30.00	24.00	20.00	14	2	3	12.00	25.33	16.15	EP3024	28.20	22.20

¹ All Window Door latch types are quarter turns.

