


RJS102-10L-H-R/D-COLOUR-BS-Voltage-67D

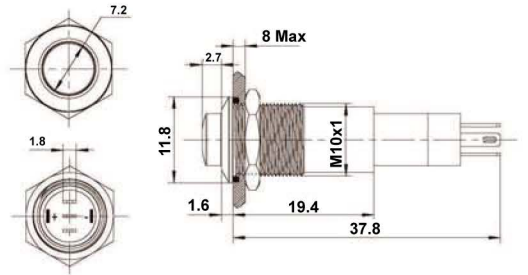


RJS102-10-H

Diameter: 10mm
 Switch Rating: 3A/250VAC
 Contact Configuration: 1NO1NC
 Operation Type: Momentary / Maintained
 The Front Shape: High
 lamp type: Dot Illuminated:(LED)
 The Crust Material: Stainless steel
 IP Degree: IP67,IK10




RJS102-10L-H-R

Diameter: 10mm
 Switch Rating: 3A/250VAC
 Contact Configuration: 1NO1NC
 Operation Type: Momentary / Maintained
 The Front Shape: High
 lamp type: Dot Illuminated:(LED)
 The Crust Material: Stainless steel
 IP Degree: IP67,IK10

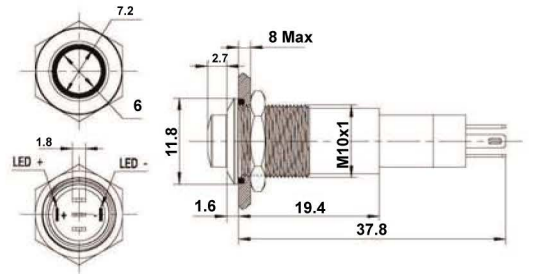

RJS-102-10L-D

Diameter: 10mm
 Switch Rating: 3A/250VAC
 Contact Configuration: 1NO1NC
 Operation Type: Momentary / Maintained
 The Front Shape: High
 lamp type: Dot Illuminated:(LED)
 The Crust Material: Stainless steel
 IP Degree: IP67,IK10

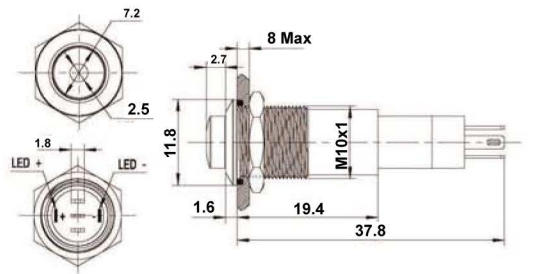

Specification	RJS102-10L-H
Terminal Type	Pin Terminal(1.8 x 0.4mm)
Switching	No.3
Max. Switch Rating	3A/250VAC
Contact Resistance	<50Mohm
Insulation Resistance	>1000Mohm
Dielectric Intensity	2000VAC
Operating Temperature	-20C ~ +55C
Mechanical life	1,000,000 cycles
Electrical Life	200,000 cycles
Panel Thickness	1-6mm
Torque	5-14Nm
Operation Pressure	About 5N
Operation Travel	About 2.5mm
IP Degree	IP67, IK08
Contact	Silver alloy
Button	Stainless steel
Body	Stainless steel
Base	PC
RoHS	Made to order