


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **5056061200**
Status: **Active**
Overview: CP Wire-to-Board and Wire-to-Wire Connector Systems
Description: CP-3.3 Plug Housing, 3.30mm Pitch, Dual Row, Polarized, Positive Inertia Lock, 12 Circuits, Natural

Documents:

Drawing (PDF)	Packaging Specification 5056069200-200 (PDF)
Product Specification 5056050000-000 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification 5056050000-A00 (PDF)	Product Literature (PDF)
Application Specification 5056050000-A01 (PDF)	

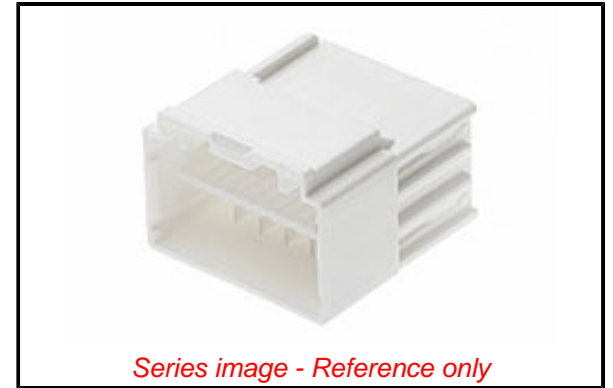

General

Product Family	Crimp Housings
Series	505606
Application	Signal, Wire-to-Wire
Overview	CP Wire-to-Board and Wire-to-Wire Connector Systems
Product Literature Order No	987651-6581
Product Name	CP-3.3
UPC	889056804646

Physical

Circuits (maximum)	12
Color - Resin	Natural
Gender	Plug
Glow-Wire Compliant	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	4548.000/mg
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.30mm
Pitch - Termination Interface	3.30mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Material Info

Reference - Drawing Numbers

Application Specification	5056050000-A00, 5056050000-A01
Packaging Specification	5056069200-200
Product Specification	5056050000-000
Sales Drawing	5056060000-000

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[505606](#) Series

Mates With

Receptacle Housing [505605-1200](#)

Use With

Terminal Retainer [504695](#) . Plug Crimp Terminal [50398](#) , [505608](#)