


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0151310205
Status: Active
Overview: Pico-Lock Connector System
Description: Pico-Lock-to-Pico-Lock Off-the-Shelf (OTS) Cable Assembly, 1.00mm Pitch, Single Row, 450.00mm Length, 2 Circuits, Black

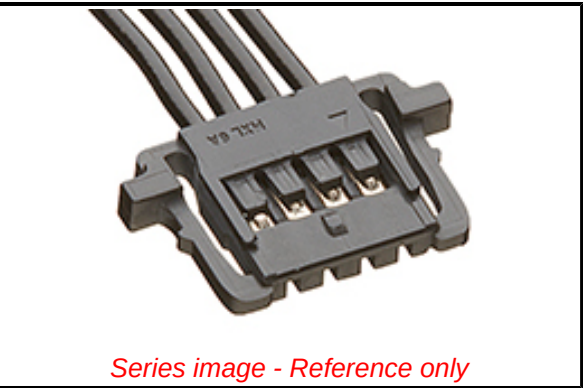

Documents:
[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	15131
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Pico-Lock-to-Pico-Lock
Overview	Pico-Lock Connector System
Product Literature Order No	987651-6143
Product Name	Pico-Lock OTS
UPC	191128284738
Physical	
Cable Length	450.00mm
Circuits (Loaded)	2
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	1.523/g
Pitch - Mating Interface	1.00mm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.60mm
Wire Size AWG	28
Wire/Cable Type	UL 1571
Electrical	
Voltage - Maximum	150V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	151310200-000

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - ED/30/2017 (7 July 2017) Halogen-Free Status Not Low-Halogen Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[15131](#) Series

Mates With
[503763](#) Pico-Lock Wire-to-Board Header

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION