


Produktname | *Product name*: M350F
 Artikelnummer | *Part Number*: 1600-0172
 Anfragenummer | *Inquiry Number*: AN201617
 Ersteller / Datum | *Creator / Date*: LHE / 2017-02-13

Version	Change	Date	Name
V0	---	2017-02-13	LHE

Template name: Light (Non-Rechargeable), Template version: V5

Leuchte / light

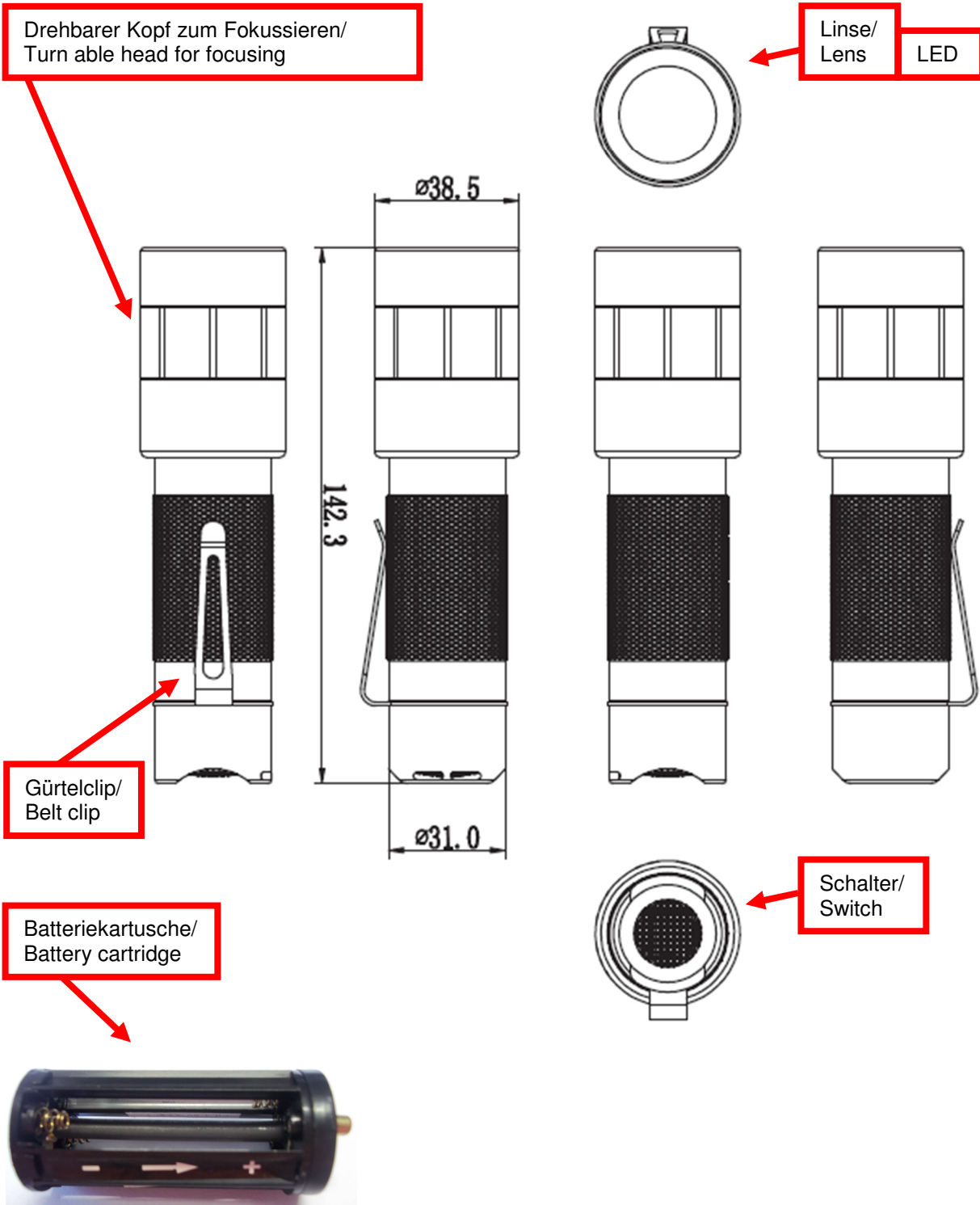

Allowable deviation / general tolerances DIN ISO 2768-c

Technische Daten der Leuchte / technical data of the light:



Haupt-LED-Leuchtmittel:	5W LED (Fokussierbar)	Main LED illuminant:	5W LED (Focus able)
Schalterfunktion:	0. Morse (tippen)	Switch function:	0. morse (tap)
	1. schalten: 100%		1. swicht: 100%
	2. tippen: boost		2. tap: boost
	3. tippen: 30%		3. tap: 30%
	4. tippen: Strobe		4. tap: strobe
	5. schalten: Aus		5. switch: Aus

Lichtstrom: [Lumen]		Luminous flux (light output): [Lumen]	
Boost:	320lm	Boost:	320lm
100%	200lm	100%	200lm
30%	60lm	30%	60lm
Leuchtdauer:		Run time:	
Boost:	ca. 1h 30min	Boost:	approx. 1h 30min
100%	ca. 4h 00min	100%	approx. 4h 00min
30%	ca. 12h 00min	30%	approx. 12h 00min
Leuchtweite:		Beam distance:	
Boost:	140m	Boost:	140m
100%	105m	100%	105m
30%	60m	30%	60m
Maximale Beleuchtungsstärke: [Lux]		Peak beam illuminance: [Lux]	
Boost:	4600lx (Abstand:1m)	Boost:	4600lx (Distance:1m)
100%	2700lx (Abstand:1m)	100%	2700lx (Distance:1m)
30%	920lx (Abstand:1m)	30%	920lx (Distance:1m)
Risikogruppe (EN 62471; Bewertet nach DIN IEC/TR 62778 Anhang C.2)	2	Risk group (EN 62471; Assessed with TR 62778 Annex C.2)	2

Benötigte Zellen:	4 x AAA Micro 1.5V Batterien (Alkaline; LR03/AM4/MN2400)	Battery:	4 x AAA Micro 1.5V batteries (Alkaline; LR03/AM4/MN2400)
Schutzart des Gehäuses:	IP54	Degree of protection by the enclosure:	IP54
Gehäusematerial:	Aluminium	Housing material:	Aluminium
Betriebstemperatur:	-10°C...25°C	Operating temperature:	-10°C...25°C
Lagertemperatur:	-10°C...50°C (Nur Alkaline Batterien) -20°C...70°C (Nur Lampe)	Storage temperature:	-10°C...50°C (Alkaline batteries only) -20°C...70°C (Torch only)
Empfohlene Lagerbedingungen: (Nur Alkaline Batterie/Batterien)	Temperatur: 5..25°C Luftfeuchtigkeit: 45..75%	Recommended storage conditions: (Alkaline battery/batteries only)	Temperature: 5...25°C Rel. humidity: 45...75 %
Approbationen:	CE	Approvals:	CE
Gewicht:	197g nur die Lampe	Weight:	197g only the torch

	241g mit 4 x Batterien (wie oben beschrieben)		<i>241g with 4 x batteries (as described above)</i>
Lieferumfang:	<ul style="list-style-type: none"> - 4 x Batterien (wie oben beschrieben) - Tragegurt - Gürtelclip - Batteriekartusche 	<i>Shipment:</i>	<ul style="list-style-type: none"> - <i>4 x batteries (as described above)</i> - <i>Lanyard</i> - <i>Belt clip</i> - <i>Battery cartridge</i>
Verpackung:	Blister-Verpackung	<i>Package:</i>	<i>Blister shell</i>