

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **1300640206**
Status: **Active**
Overview: Brad® Quick-Change® Connectors
Description: Quick-Change Double-Ended Cordset, 4 Poles, Female (Straight) to Male (Straight), 10 AWG, PVC Cable, 4.0m (13.12') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Industrial Cordsets
 Series 130064
 Connector End A Quick-Change
 Connector End B Quick-Change
 IP Rating IP67
 Material - Contact Copper Alloy
 Overview Brad® Quick-Change® Connectors
 Product Name Quick-Change
 Protocol EtherNet
 Region Europe
 Type Double Ended
 UPC 78678882499

Physical

Cable Diameter 5.08mm (.200")
 Cable Length 4.0m (13.12')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Female-Male
 Keyway Single
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Anodized Aluminum
 Material - Plating Mating Gold over Nickel
 Orientation Straight to Straight
 Poles 4
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 10
 Wire/Cable Type ST00W, TC-ER Direct Burial

Electrical


Current - Maximum per Contact 25.0A
 Voltage - Maximum 600V

Material Info

Engineering Number CC4030A48M040

Reference - Drawing Numbers

Sales Drawing SD-130064-065

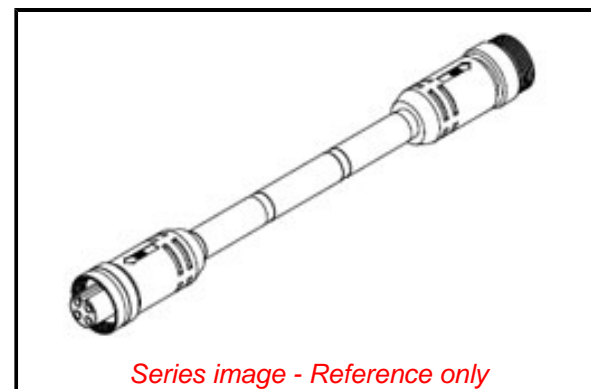

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

| | |
|-----------------|--------------|
| China ROHS | Not Reviewed |
| ELV | Not Relevant |
| RoHS Phthalates | Not Reviewed |

China RoHS

Search Parts in this Series

130064 Series