


Plug SLS4...-L

In-line, Ø 4 mm, with spring-loaded MULTILAM for self-assembly of test leads.

Soft insulator.

Solder connection.

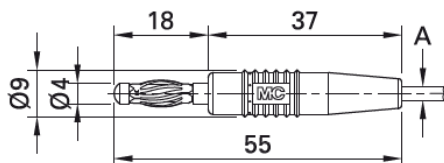

Assembly instructions MA116

www.staubli.com/electrical

Order No.	Type	Rated voltage/current	Cable (A)		*Colors												
22.2646-*	SLS410-L	30 VAC / 19 A 60 VDC / 19 A	Ø 3.0 mm	1.0 mm ²	<table border="1"> <tr> <td>Au</td> <td>21</td> <td>22</td> <td>23</td> <td>24</td> <td>25</td> </tr> <tr> <td></td> <td>26</td> <td>27</td> <td>28</td> <td>29</td> <td></td> </tr> </table>	Au	21	22	23	24	25		26	27	28	29	
Au	21	22	23	24	25												
	26	27	28	29													

Component parts

22.2170-*	KT410-L	Insulator for SLS410-L
22.1011	LS410-L	Plug for SLS410-L