


Socket SLS4...-B

Ø 4 mm, rigid, for self-assembly of test leads. Soft insulator.
Solder connection.

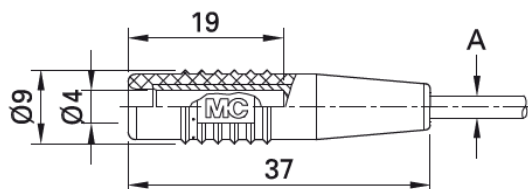

Order No.	Type	Rated voltage/current	Cable (A)			*Colors										
22.2649-*	SLS410-B	30 VAC / 19 A 60 VDC / 19 A	max. Ø 3.0 mm	1.0 mm ²	Au	<table><tr><td>21</td><td>22</td><td>23</td><td>24</td><td>25</td></tr><tr><td>26</td><td>27</td><td>28</td><td>29</td><td></td></tr></table>	21	22	23	24	25	26	27	28	29	
21	22	23	24	25												
26	27	28	29													

Component parts

22.2170-*	KT410-L	Insulator for SLS410-B
22.1012	LS410-B	Socket for SLS410-B



Assembly instructions MA117

www.staubli.com/electrical