


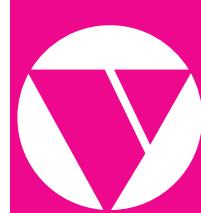

Vynckier

ENCLOSURE SYSTEMS INC.



Multibox Series • Multi Purpose Boxes

For Electrical, Electronic and Industrial Applications

** Suffix

PC: Polycarbonate opaque cover enclosures with four non-metallic corner screws

PCCT: Polycarbonate transparent cover enclosures with four non-metallic corner screws

PCK: Polycarbonate opaque cover enclosures with four non-metallic corner screws and metric knockouts

PCCTK: Polycarbonate enclosures with four non-metallic corner screws and metricknockouts

PS: Polystyrene opaque cover enclosures with four non-metallic corner screws

PSCT: Polystyrene transparent cover enclosures with four non-metallic corner screws

PSK: Polystyrene opaque cover enclosures with four non-metallic corner screws and metric knockouts

PSCTK: Polystyrene enclosures with four non-metallic corner screws and metricknockouts

Features

- Enclosures are maintenance free and corrosion resistant.
- PC bases and covers are made from polycarbonate that can withstand continuous temperatures from -31°F to 176°F (-35°C to 80°C).
- PCCT bases and covers are made from polycarbonate that can withstand continuous temperatures from -31°F to 176°F (-35°C to 80°C).
- PS bases and covers are made from polystyrene that can withstand continuous temperatures from -13°F to +104°F (-25°C to +40°C).
- PSCT bases are made from polystyrene and covers are made from polycarbonate that can withstand continuous temperatures from -13°F to 104°F (-25°C to 40°C).
- Cover screw holes in corners are outside of the gasketed area.
- Continuous gaskets made of polyurethane foam guarantee optimal integrity.
- All enclosures can be easily modified to customer specifications.

Applications

The Multibox series enclosures are designed for use as electrical junction boxes or instrumentation enclosures in highly corrosive environments.

Standards

IEC 60529 (IP66)

IEC 50102 (IK08) Polycarbonate

IEC 50102 (IK07) Polystyrene

EN 60529 (IP66)

EN 50102 (IK08) Polycarbonate

EN 50102 (IK07) Polystyrene

Approvals

UL Listed Types 4X & 12 (Polycarbonate)

NEMA 4X & 12 (Polystyrene)



Rev 01/12/16





Multibox Series Data Sheet

Rev 01/12/16

Part Number ** Suffix (ex. MB252502PCCTK)	Exterior Dimensions H x W x D Inches (mm)	Interior Dimensions H x W x D Inches (mm)	Weight Lbs (kg)	Back Plate A: Aluminum S: Steel N: Non-Metallic
MB252502PC** MB252502PS**	2.55 x 2.55 x 2.25 (65 x 65 x 57)	2.32 x 2.32 x 1.77 (59 x 59 x 45)	.11 (.05)	MBBP2525A, MBBP2525S, MBBP2525N
MB252503PC** MB252503PS**	2.55 x 2.55 x 3.18 (65 x 65 x 81)	2.32 x 2.32 x 2.72 (59 x 59 x 69)	.16 (.07)	MBBP2525A, MBBP2525S, MBBP2525N
MB042502PC** MB042502PS**	3.70 x 2.55 x 2.25 (94 x 65 x 57)	2.32 x 2.32 x 1.77 (88 x 59 x 45)	.16 (.07)	MBBP0425A, MBBP0425S, MBBP0425S
MB042503PC** MB042503PS**	3.70 x 2.55 x 3.18 (94 x 65 x 81)	3.46 x 2.32 x 2.72 (88 x 59 x 69)	.21 (.10)	MBBP0425A, MBBP0425S, MBBP0425N
MB040402PC** MB040402PS**	3.70 x 3.70 x 2.24 (94 x 94 x 57)	3.46 x 3.46 x 1.77 (88 x 88 x 45)	.23 (.10)	MBBP44A, MBBP44S, MBBP44N
MB040403PC** MB040403PS**	3.70 x 3.70 x 3.18 (94 x 94 x 81)	3.46 x 3.46 x 2.72 (88 x 88 x 69)	.28 (.13)	MBBP44A, MBBP44S, MBBP44N
MB040425PC** MB040425PS**	4.33 x 4.33 x 2.60 (110 x 110 x 66)	4.09 x 4.09 x 2.13 (104 x 104 x 54)	.32 (.15)	MBBP0404A, MBBP0404S, MBBP0404N
MB040435PC** MB040435PS**	4.33 x 4.33 x 3.54 (110 x 110 x 90)	4.09 x 4.09 x 3.07 (104 x 104 x 78)	.37 (.17)	MBBP0404A, MBBP0404S, MBBP0404N
MB050402PC** MB050402PS**	5.11 x 3.70 x 2.24 (130 x 94 x 57)	4.88 x 3.46 x 1.77 (124 x 88 x 45)	.32 (.15)	MBBP0504A, MBBP0504S, MBBP0504N
MB050403PC** MB050403PS**	5.11 x 3.70 x 3.19 (130 x 94 x 81)	4.88 x 3.46 x 2.72 (124 x 88 x 69)	.37 (.17)	MBBP0504A, MBBP0504S, MBBP0504N
MB050503PC** MB050503PS**	5.11 x 5.11 x 2.95 (130 x 130 x 75)	4.88 x 4.88 x 2.48 (124 x 124 x 63)	.44 (.20)	MBBP0505A, MBBP0505S, MBBP0505N
MB050504PC** MB050504PS**	5.11 x 5.11 x 3.90 (130 x 130 x 99)	4.88 x 4.88 x 3.43 (124 x 124 x 87)	.49 (.22)	MBBP0505A, MBBP0505S, MBBP0505N
MB070402PC** MB070402PS**	7.08 x 3.70 x 2.24 (180 x 94 x 57)	6.85 x 3.46 x 1.77 (174 x 88 x 45)	.45 (.20)	MBBP74A, MBBP74S, MBBP74S
MB070403PC** MB070403PS**	7.08 x 3.70 x 3.19 (180 x 94 x 81)	6.85 x 3.46 x 2.72 (174 x 88 x 69)	.50 (.23)	MBBP74A, MBBP74S, MBBP74N
MB070435PC** MB070435PS**	7.08 x 4.33 x 3.54 (180 x 110 x 90)	6.81 x 4.06 x 2.95 (173 x 103 x 75)	.52 (.24)	MBBP0704A, MBBP0704S, MBBP0704N
MB070404PC** MB070404PS**	7.08 x 4.33 x 4.37 (180 x 110 x 111)	6.81 x 4.06 x 3.82 (173 x 103 x 97)	.57 (.27)	MBBP0704A, MBBP0704S, MBBP0704N
MB070465PC** MB070465PS**	7.08 x 4.33 x 6.50 (180 x 110 x 165)	6.81 x 4.06 x 5.91 (173 x 103 x 150)	.67 (.30)	MBBP0704A, MBBP0704S, MBBP0704N
MB070735PC** MB070735PS**	7.08 x 7.17 x 3.54 (180 x 182 x 90)	6.85 x 6.93 x 2.95 (174 x 176 x 75)	.86 (.39)	MBBP0707A, MBBP0707S, MBBP0707N
MB070704PC** MB070704PS**	7.08 x 7.17 x 4.37 (180 x 182 x 111)	6.85 x 6.93 x 3.82 (174 x 176 x 97)	.91 (.41)	MBBP0707A, MBBP0707S, MBBP0707N
MB070765PC** MB070765PS**	7.08 x 7.17 x 6.46 (180 x 182 x 164)	6.85 x 6.93 x 5.94 (174 x 176 x 151)	1.01 (.46)	MBBP0707A, MBBP0707S, MBBP0707N
MB100735PC** MB100735PS**	10.00 x 7.09 x 3.54 (254 x 180 x 90)	9.76 x 6.85 x 2.95 (248 x 174 x 75)	1.21 (.55)	MBBP1007A, MBBP1007S, MBBP1007N
MB100704PC** MB100704PS**	10.00 x 7.09 x 4.37 (254 x 180 x 111)	9.76 x 6.85 x 3.82 (248 x 174 x 97)	1.26 (.57)	MBBP1007A, MBBP1007S, MBBP1007N
MB100765PC** MB100765PS**	10.00 x 7.09 x 6.50 (254 x 180 x 165)	9.76 x 6.85 x 5.94 (248 x 174 x 151)	1.36 (.62)	MBBP1007A, MBBP1007S, MBBP1007N
MB141004PC** MB141004PS**	14.21 x 10.00 x 4.37 (361 x 254 x 111)	13.98 x 9.76 x 3.82 (355 x 248 x 97)	2.42 (1.10)	MBBP1410A, MBBP1410S, MBBP1410N
MB141065PC** MB141065PS**	14.21 x 10.00 x 6.46 (361 x 254 x 164)	13.98 x 9.76 x 5.91 (355 x 248 x 150)	2.52 (1.14)	MBBP1410A, MBBP1410S, MBBP1410A