

Countersunk Head Slotted Screw




**RoHS
Compliant**



Specifications

Material : Nylon 66
Colour : Natural

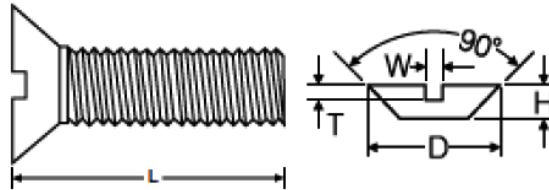

Dimension Table

Part Number	Thread Size	"L" Length	Screw Size	D	H	T	W
121020006	M2 x 0.4	6	M2	3.8	1.2	0.5	0.5
121020010	M2 x 0.4	10	M2	3.8	1.2	0.5	0.5
121020012	M2 x 0.4	12	M2	3.8	1.2	0.5	0.5
121020016	M2 x 0.4	16	M2	3.8	1.2	0.5	0.5
121030006	M3 x 0.5	6	M3	5.6	1.65	0.7	0.8
121030010	M3 x 0.5	10	M3	5.6	1.65	0.7	0.8
121030012	M3 x 0.5	12	M3	5.6	1.65	0.7	0.8
121030016	M3 x 0.5	16	M3	5.6	1.65	0.7	0.8
121030020	M3 x 0.5	20	M3	5.6	1.65	0.7	0.8
121030025	M3 x 0.5	25	M3	5.6	1.65	0.7	0.8
121030030	M3 x 0.5	30	M3	5.6	1.65	0.7	0.8
121040012	M4 x 0.7	12	M4	7.5 - 9.4	2.7	1.3	1.5
121040016	M4 x 0.7	16	M4	7.5 - 9.4	2.7	1.3	1.5
121040020	M4 x 0.7	20	M4	7.5 - 9.4	2.7	1.3	1.5
121040025	M4 x 0.7	25	M4	7.5 - 9.4	2.7	1.3	1.5
121040030	M4 x 0.7	30	M4	7.5 - 9.4	2.7	1.3	1.5

Dimensions : Millimetres

Part Number Table

Description	Part Number
Nylon 66, Countersunk Head Slotted Screw M2 x 06, Natural	121020006
Nylon 66, Countersunk Head Slotted Screw M2 x 10, Natural	121020010
Nylon 66, Countersunk Head Slotted Screw M2 x 12, Natural	121020012
Nylon 66, Countersunk Head Slotted Screw M2 x 16, Natural	121020016
Nylon 66, Countersunk Head Slotted Screw M3 x 6, Natural	121030006
Nylon 66, Countersunk Head Slotted Screw M3 x 10, Natural	121030010



Countersunk Head Slotted Screw



Description	Part Number
Nylon 66, Countersunk Head Slotted Screw M3 × 12, Natural	121030012
Nylon 66, Countersunk Head Slotted Screw M3 × 16, Natural	121030016
Nylon 66, Countersunk Head Slotted Screw M3 × 20, Natural	121030020
Nylon 66, Countersunk Head Slotted Screw M3 × 25, Natural	121030025
Nylon 66, Countersunk Head Slotted Screw M3 × 30, Natural	121030030
Nylon 66, Countersunk Head Slotted Screw M4 × 12, Natural	121040012
Nylon 66, Countersunk Head Slotted Screw M4 × 16, Natural	121040016
Nylon 66, Countersunk Head Slotted Screw M4 × 20, Natural	121040020
Nylon 66, Countersunk Head Slotted Screw M4 × 25, Natural	121040025
Nylon 66, Countersunk Head Slotted Screw M4 × 30, Natural	121040030

Important Notice : This data sheet and its contents (the "Information") belong to the members of the Premier Farnell group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. DURATOOL is the registered trademark of the Group. © Premier Farnell Limited 2016.

