


Black Part No. **C2RR247023DBK1**

Beige Part No. **C2RR247023DCG1**

Specifications

- 24" wide rack mount or 19" wide rack mount (**CAK1924** adapter kit required)
- 70" (40U) panel height
- 23.63" overall depth

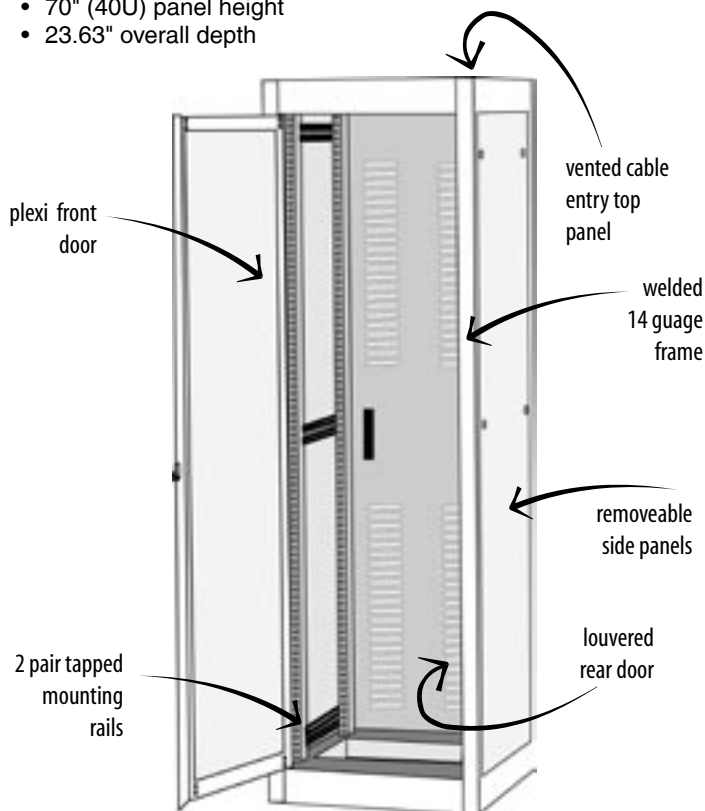

Features

- Shipped fully assembled
- Welded 14 gauge steel frame
- Removable sides, doors and top for easy access
- Open bottom for cable access
- Can be ganged side by side
- 4 mounting rails, u market, tapped 10-32 to EIA standards
- Lockable doors
- Grounding provision

| Assembly Components | Beige | Black |
|---------------------------------|-----------------------|-----------------------|
| Frame (incl. leveling feet) | C2F247023CG1* | C2F247023BK1* |
| Tapped mounting rails (2 pairs) | 2xCCR70TBK3 | 2xCCR70TBK3 |
| Plexi front door | C2DF2470PBK1 | C2DF2470PBK1 |
| Louvered rear door | CDF2470LCG1* | CDF2470LBK1* |
| Vented cable entry top panel | C2T2423VCECG1* | C2T2423VCEBK1* |
| Side panels (pair) | CSP7023CG1* | CSP7023BK1* |

* Other colors available, contact factory for details

Note: If any assembly component needs to be changed or removed, please order all parts by the component number shown.

Optional Accessories

| General Accessories | Beige | Black |
|---|----------------------|----------------------|
| Extra tapped mounting rails (pair) | — | CCR70TBK3 |
| Ganging kit | — | CGH01 |
| 24" to 19" adapter kit (for 1 pair rails) | — | CAK1924 |
| Solid door | CDF2470CG1* | CDF2470BK1* |
| Perforated Door | CDF2470VCG1* | CDF2470VBK1* |
| Vented Plexi Door | CDF2470VPCG1* | CDF2470VPBK1* |
| Side panel locks (4) | — | CSPQTRL |
| Casters (4) | — | 1425BM |
| Fan top with 4 fans | C2T2423F4CG1* | C2T2423F4BK1* |
| 10-32 x .75" Countersunk Screws | — | 1421A25B |
| 10-32 Plastic Cup Washers | — | 1421A25W |
| 10-32 x.63 black pan hd screw, nylon washer - 25 qty | — | 1421ABK25 |
| 10-32 x.63 black pan hd screw, nylon washer - 100 qty | — | 1421ABK100 |

19" Panel Width Accessories (requires adapter kits from above)

| | Black |
|---------------------------|------------------------|
| Solid slide-out shelf | RSUS1918BK1 |
| Vented slide-out shelf | RSVS1918BK1 |
| Solid shelf | RFUS1918BK1* |
| Vented shelf | RFVS1918BK1* |
| Keyboard drawer | RAKS19BK1 |
| Swivel keyboard drawer | RSKS19005BK1 |
| Swivel keyboard door | RSKS19DOORKB1 |
| Storage drawer | RDRW1900316BK1* |
| Filler panel (1U) | PBPA19001BK2* |
| Filler panel (2U) | PBPA19003BK2* |
| Filler panel (3U) | PBPA19005BK2* |
| Fan tray (6 fan, 600 CFM) | FT600HA1BK |

24" Panel Width Accessories

| | Black |
|-----------------|------------------------|
| Solid shelf | RFUS2418BK1* |
| Vented shelf | RFVS2418BK1* |
| Keyboard drawer | RAKS24BK1 |
| Storage drawer | RDRW2400316BK1* |

*Other colors available, contact factory for details

Power Bars

see page 16

Cable Management

see page 17-18

More Accessories

see Catalog ER-2000



24" Server Application




19" Panel Mount
(requires **CAK1924** adapter kit)

Black Part No. C2RR247823DBK1

Beige Part No. C2RR247823DCG1

Specifications

24" wide rack mount or
 19" wide rack mount (**CAK1924** adapter kit required)
 78.75" (45U) panel height
 23.63" overall depth

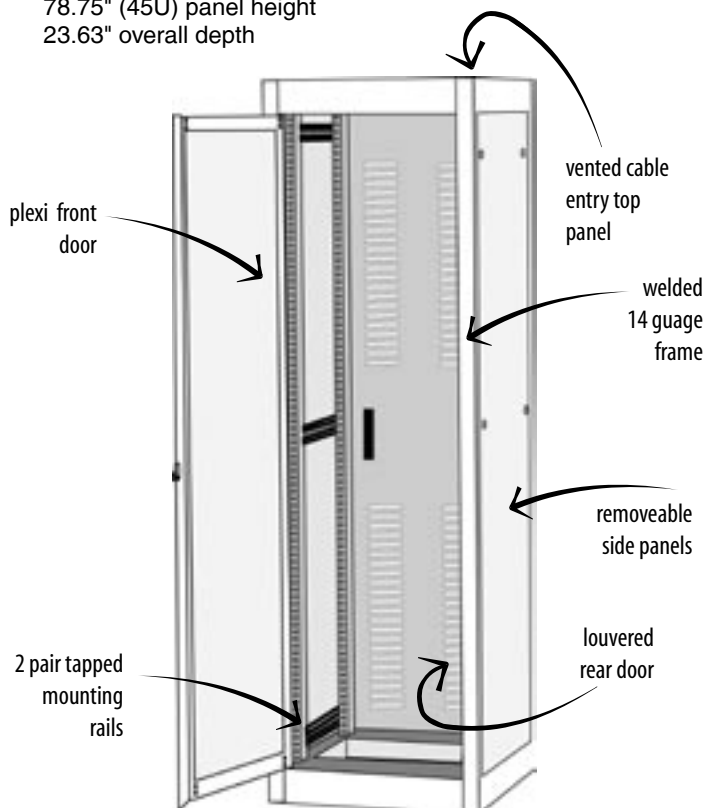

Features

Shipped fully assembled
 Welded 14 gauge steel frame
 Removable sides, doors and top for easy access
 Open bottom for cable access
 Can be ganged side by side
 4 mounting rails, u marked, tapped 10-32 to EIA standards
 Lockable doors
 Grounding provision

| Assembly Components | Beige | Black |
|---------------------------------|----------------|----------------|
| Frame (incl. leveling feet) | C2F247823CG1* | C2F247823BK1* |
| Tapped mounting rails (2 pairs) | 2xCCR78TBK3 | 2xCCR78TBK3 |
| Plexi front door | C2DF2478PBK1 | C2DF2478PBK1 |
| Louvered rear door | CDF2478LCG1* | CDF2478LBK1* |
| Vented cable entry top panel | C2T2423VCECG1* | C2T2423VCEBK1* |
| Side panels (pair) | CSP7823CG1* | CSP7823BK1* |

*Other colors available, contact factory for details

Note: If any assembly component needs to be changed or removed, please order all parts by the component number shown.

Optional Accessories

| General Accessories | Beige | Black |
|---|---------------|---------------|
| Extra tapped mounting rails (pair) | — | CCR78TBK3 |
| Ganging kit | — | CGH01 |
| 24" to 19" adapter kit (for 1 pair rails) | — | CAK1924 |
| Solid door | CDF2478CG1* | CDF2478BK1* |
| Perforated Door | CDF2478VCG1* | CDF2478VBK1* |
| Vented Plexi Door | CDF2478VPCG1* | CDF2478VPBK1* |
| Side panel locks (4) | — | CSPQTRL |
| Casters (4) | — | 1425BM |
| Fan top with 4 fans | C2T2423F4CG1* | C2T2423F4BK1* |
| 10-32 x .75" Countersunk Screws | — | 1421A25B |
| 10-32 Plastic Cup Washers | — | 1421A25W |
| 10-32 x.63 black pan hd screw, nylon washer - 25 qty | — | 1421ABK25 |
| 10-32 x.63 black pan hd screw, nylon washer - 100 qty | — | 1421ABK100 |

19" Panel Width Accessories (requires adapter kits from above)

| | Black |
|---------------------------|-----------------|
| Solid slide-out shelf | RSUS1918BK1 |
| Vented slide-out shelf | RSVS1918BK1 |
| Solid shelf | RFUS1918BK1* |
| Vented shelf | RFVS1918BK1* |
| Keyboard drawer | RAKS19BK1 |
| Swivel keyboard shelf | RSKS19005BK1 |
| Swivel keyboard door | RSKS19DOORBK1 |
| Storage drawer | RDRW1900316BK1* |
| Filler panel (1U) | PBPA19001BK2* |
| Filler panel (2U) | PBPA19003BK2* |
| Filler panel (3U) | PBPA19005BK2* |
| Fan tray (6 fan, 600 CFM) | FT600HA1BK |

24" Panel Width Accessories

| | Black |
|-----------------|-----------------|
| Solid shelf | RFUS2418BK1* |
| Vented shelf | RFVS2418BK1* |
| Keyboard drawer | RAKS24BK1 |
| Storage drawer | RDRW2400316BK1* |

*Other colors available, contact factory for details

Power Bars

see page 16

Cable Management

see page 17-18

More Accessories

see Catalog ER-2000



24" Server Application



19" Panel Mount
(requires **CAK1924** adapter kit)