


C284, Film, Film/Foil Polypropylene, Motor Run, 8 uF, 5%, 470 VAC

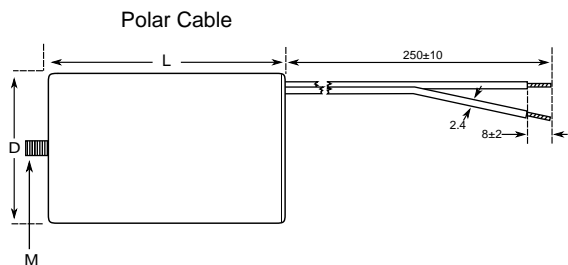

**Dimensions**

D	30mm +/-1mm
L	69.5mm +/-2mm

**Packaging Specifications**

Packaging:	Bulk, Bag
Packaging Quantity:	110

**General Information**

Supplier:	KEMET
Series:	C284
Dielectric:	Film/Foil Polypropylene
Style:	Can
Description:	Plastic Case and Cover, Ultra Sonically Welded Seal
Features:	Ultra Sonically Welded Seal, Safety Class P0, UL_94 V0 Disk
RoHS:	Yes
Termination:	Tin Copper
Lead:	Cables
Approvals:	UL, VDE, UL (Construction Only), UL_94 V0 Disk

**Specifications**

Capacitance:	8 uF
Capacitance Tolerance:	5%
Voltage AC:	470 VAC
Temperature Range:	-25/+85C
Rated Temperature:	85C
Max dVdt:	20 V