

Screw-Terminal Surface-Mount N.O. Contacts

SM-300Q/BR

1/2" (13mm) Gap, Open Loop, Brown, with Mounting Tabs

SM-300Q/W


1/2" (13mm) Gap, Open Loop, White, with Mounting Tabs

Features:

- Surface-mount magnetic contacts
- Screw mount using side tabs
- Terminal cover provided (required for all applications)
- ABS plastic case has lip to prevent wires from accidentally touching metal mountings and slotted mounting holes for easier gap adjustment
- Contact reed switch is SPST, deactivated rhodium on gold under-plating for a longer expected life
- 1/2" (13mm) Gap
- For open loop circuits
- Mounting screws included
- Lifetime limited warranty




SM-300Q/W shown

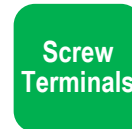

Specifications:

| | | |
|-------------------|--------------------------------------|---|
| Model number | SM-300-Q/BR | SM-300-Q/W |
| Circuit type | Open loop | |
| Operation gap | 1/2" (13mm) | |
| Color | Brown | White |
| Terminals | Screw-type | |
| Mounting tabs | Yes | |
| Material | Case | High-impact ABS plastic |
| | Contacts | Deactivated rhodium on gold under-plating |
| Contact rating | 0.1A@100VDC (max) | |
| | 1.0A@10VDC (max) | |
| | 10W (max) | |
| Temperature | -15°~160°F (-25°~70°C) | |
| Switch cycles | 50 Million (0.1mA@5VDC) | |
| Switch dimensions | 2 1/2" x 9/16" x 1/2" (63.5x14x13mm) | |
| Magnet dimensions | 2 1/2" x 1/2" x 1/2" (63.5x13x13mm) | |
| Magnet type | Ferrite | |

Dimensions:

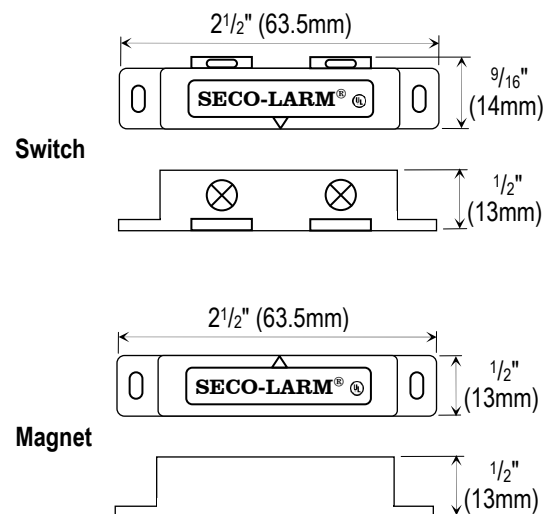

SECO-LARM® U.S.A., Inc.

16842 Millikan Avenue, Irvine, CA 92606

Phone: (949) 261-2999 | (800) 662-0800 Fax: (949) 261-7326

Website: www.seco-larm.com Email: sales@seco-larm.com



Copyright 2015 © SECO-LARM U.S.A., Inc. All rights reserved. All trademarks are the property of SECO-LARM U.S.A., Inc. or their respective owners. The SECO-LARM policy is one of continual development. For that reason, SECO-LARM reserves the right to change prices and specifications without notice. SECO-LARM is not responsible for misprints.

SECO-LARM® ENFORCER® CRIMEBUSTER® CBA SLI

PiSM-300Q_150504.docx