


Share:

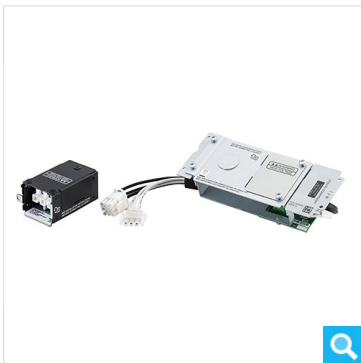

SRT012



Be the first to [write a review](#)

Includes : Installation guide , Warranty card



Product Overview **Technical Specifications** Documentation Ratings & Reviews

Output

Print Technical Specification

Nominal Output Voltage 120V , 208V , 230V , 240V

Output Connections

(1) Hard Wire 3-wire (H N + G) (Battery Backup)

Input

Nominal Input Voltage 120V , 208V , 230V , 240V

Input Connections

Hard Wire 3-wire (2PH + G), Hard Wire 3 wire (1PH+N+G)

Physical

Maximum Height 3.07inches (78mm , 7.8CM)

Maximum Width 7.56inches (192mm , 19.2CM)

Maximum Depth 3.35inches (85mm , 8.5CM)

Net Weight 1.5lbs. (0.68KG)

Shipping weight 2.2lbs. (1.0KG)

Shipping Height 5.55inches (141mm , 14.1CM)

Shipping Width 7.01inches (178mm , 17.8CM)

Shipping Depth 10.0inches (254mm , 25.4CM)

Units per Pallet 144.0

Sustainable Offer Status

RoHS Compliant

REACH REACH: Contains No SVHCs



Sign up to stay up to date with best practices, new solutions and special offers.

Email

I am a...

OK

WHO WE ARE

- APC History
- Investor Relations
- Careers
- Sustainability

CONNECT WITH US

- Press
- APC Blog
- Schneider Electric TV
- Schneider Electric Data Center Blog
- Contact Us
- Rate this website

FIND A RESELLER

Zip/Postal Code FIND

CATALOG KEYCODE

Enter Key Code GO

