
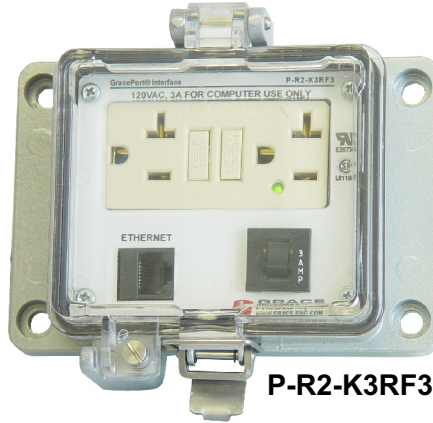


GracePort® Ethernet Port Connector Code Data Sheet

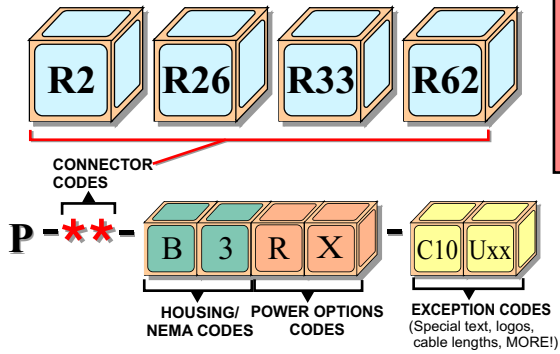

Grace has your ethernet access solution.

CONNECTOR CODE	DESCRIPTION
	CATEGORY 5 RJ45 F/F BULKHEAD
	CATEGORY 5 RJ45 F/IDT BULKHEAD
	CATEGORY 5 SHIELDED RJ45 F/F BULKHEAD
	CATEGORY 6 RJ45 F/F BULKHEAD

⚠️ INSTALLATION

GracePorts® are intended to be mounted in or on an enclosure product. Installation should be performed by a qualified technician and adhere to applicable regulatory codes. These devices are for mounting on the flat surface of enclosures having the same type of environmental rating.

SPECIFICATIONS: ELECTRICAL

Low voltage (data), limited to 30 VDC
 High voltage supply (for computer use only)
 120 VAC, 15A (UL), 5A (CSA)
 230-240 VAC, 16A (CE only)

SPECIFICATIONS: MECHANICAL

Housing: Cast aluminum base
 Latch: Type 304 Stainless Steel (1CR18NI19)
 Cover: Polycarbonate, UV rated, V-O Flame rated
 Gasket: Thermoplastic elastomer
 Insert Material: Acrylic UL94HB

APPROVALS

UL RECOGNIZED: E207344 (Outdoor Use)
 CSA: LR110845 (not for interrupting circuit)
 CE: EN61010/EN60950 (Foreign Power Outlets)



5001 Tremont Avenue
 Davenport, IA 52807
 (800) 280-9517 Fax: (563) 386-9639

©2006 Grace Engineered Products, Inc.
 GracePort® is a registered Trademark of Grace Engineered Products, Inc.
 DataSheets:Ethernet:12/2007