

03

0380


Circular connectors with threaded joint M16 acc. to IEC 61076-2-106, IP40/IP67/IP68



Wrench for plugs and sockets IP68

03

0380

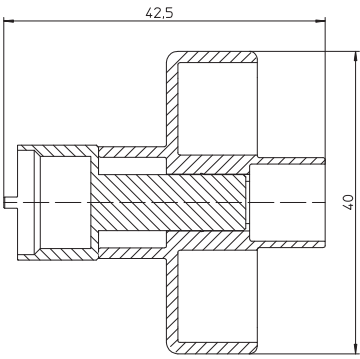

Environmental conditions

Temperature range -40 °C/+85 °C

Associated products

03

0380

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
0380	-	1	1

Packaging:

in a cardboard box