


Product description **Protection cap for female panel mount connector**
 Order number **08 0352 000 001**

Illustration



Scale drawing

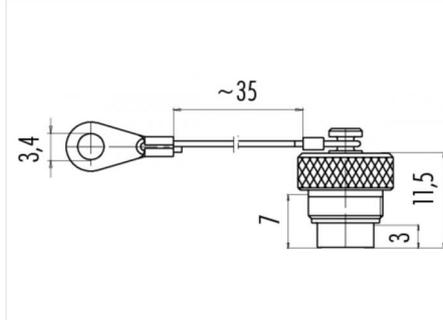

Technical data

Degree of protection IP67

Matching products

- 09 0404 00 02 - Female panel mount connector, solder
- 09 0408 00 03 - Female panel mount connector, solder
- 09 0412 00 04 - Female panel mount connector, solder
- 09 0416 00 05 - Female panel mount connector, solder
- 09 0424 00 07 - Female panel mount connector, solder
- 09 0428 00 08 - Female panel mount connector, solder
- 09 0404 80 02 - Female panel mount connector, solder, screwed from front
- 09 0408 80 03 - Female panel mount connector, solder, screwed from front
- 09 0412 80 04 - Female panel mount connector, solder, screwed from front
- 09 0416 80 05 - Female panel mount connector, solder, screwed from front
- 09 0424 80 07 - Female panel mount connector, solder, screwed from front
- 09 0428 80 08 - Female panel mount connector, solder, screwed from front
- 09 0404 90 02 - Female panel mount connector, dip-solder, screwed from front
- 09 0408 90 03 - Female panel mount connector, dip-solder, screwed from front
- 09 0412 90 04 - Female panel mount connector, dip-solder, screwed from front
- 09 0416 90 05 - Female panel mount connector, dip-solder, screwed from front
- 09 0424 90 07 - Female panel mount connector, dip-solder, screwed from front
- 09 0428 90 08 - Female panel mount connector, dip-solder, screwed from front
- 09 0404 30 02 - Female panel mount connector, dip-solder, screwed from front with shielding sheet (6 mm)
- 09 0408 30 03 - Female panel mount connector, dip-solder, screwed from front with shielding sheet (6 mm)
- 09 0412 30 04 - Female panel mount connector, dip-solder, screwed from front with shielding sheet (6 mm)
- 09 0416 30 05 - Female panel mount connector, dip-solder, screwed from front with shielding sheet (6 mm)
- 09 0424 30 07 - Female panel mount connector, dip-solder, screwed from front with shielding sheet (6 mm)
- 09 0428 30 08 - Female panel mount connector, dip-solder, screwed from front with shielding sheet (6 mm)
- 09 0404 35 02 - Female panel mount connector, dip-solder, screwed from front with shielding sheet (10 mm)
- 09 0408 35 03 - Female panel mount connector, dip-solder, screwed from front with shielding sheet (10 mm)
- 09 0412 35 04 - Female panel mount connector, dip-solder, screwed from front with shielding sheet (10 mm)
- 09 0416 35 05 - Female panel mount connector, dip-solder, screwed from front with shielding sheet (10 mm)
- 09 0424 35 07 - Female panel mount connector, dip-solder, screwed from front with shielding sheet (10 mm)
- 09 0428 35 08 - Female panel mount connector, dip-solder, screwed from front with shielding sheet (10 mm)
- 09 0404 55 02 - Female panel mount connector, dip-solder, screwed from front with shielding sheet, angled
- 09 0416 55 05 - Female panel mount connector, dip-solder, screwed from front with shielding sheet, angled
- 09 0424 65 07 - Female panel mount connector with flexible printed circuit board (PCB), contacts 7
- 09 0428 65 08 - Female panel mount connector with flexible printed circuit board (PCB), contacts 8