



< List of part numbers with package codes >
ECASD40E337M006K00

Shape

L size	7.3 ±0.3mm
W size	4.3 ±0.2mm
T size	1.9 ±0.1mm
W1 size (max.)	2.4±0.2mm
S size	1.3±0.2mm
Size code in inch(mm)	2917(7343)

References

Packaging	Specifications	Minimum quantity
K	φ330mm Embossed taping	3000







Mass (typ.)	
1 piece	0.13g

Specifications

ESR (equivalent series resistance)	6mΩ
Capacitance	330μF ±20%
Rated voltage	2.5Vdc
Capacitance change rate	±20%
Operating temperature range	-40~105°C
Allowable Ripple Current	3.5 Arms
Leakage Current	82.5 μA

⚠ Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
2.This datasheet has only typical specifications because there is no space for detailed specifications.
Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

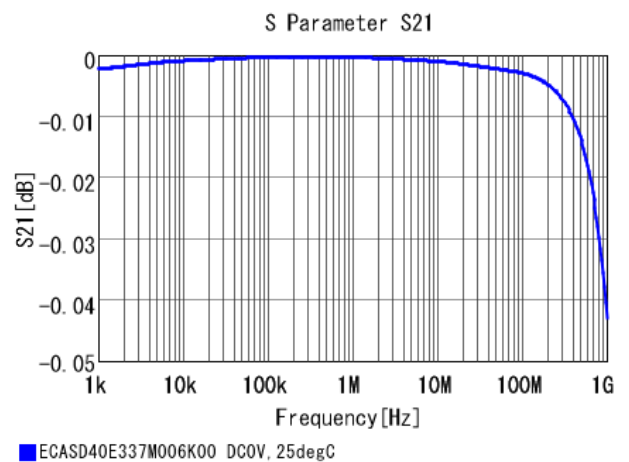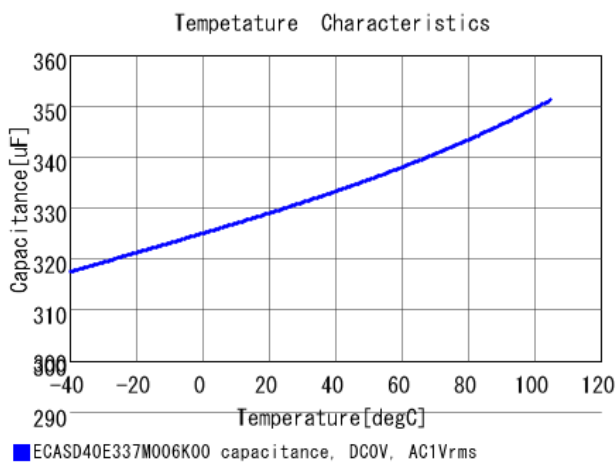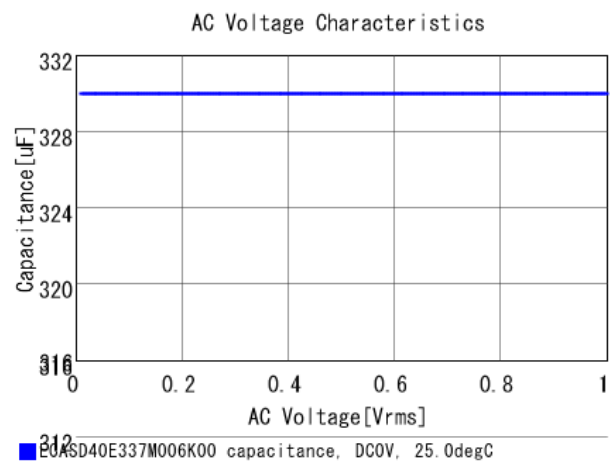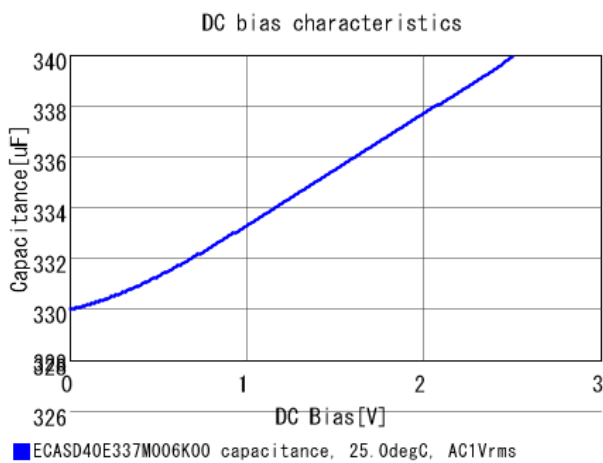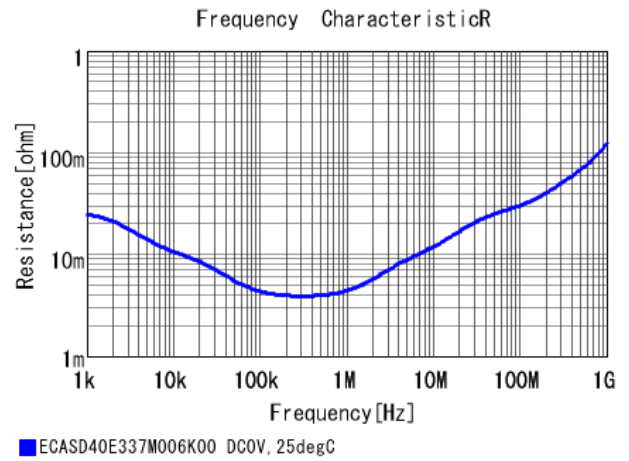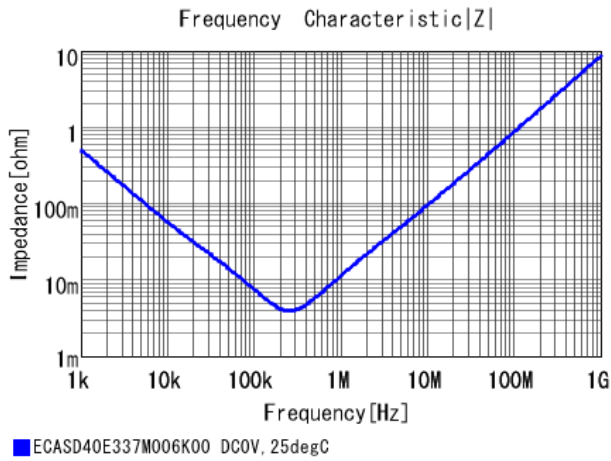

Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
 - 2.This datasheet has only typical specifications because there is no space for detailed specifications.
- Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.