

**Wiha Powerhandle TORX®** Made in Germany



**362 TORX® Screwdriver, With Wiha-Powerhandle** CVM steel blade, hardened, hard chromed. Wiha-powerhandle cellulose-acetate.



**36292 8 Pc. Set TORX®** Blade high alloy CVM steel, hardened, hard chromed. Wiha-powerhandle cellulose-acetate, impact resistant.

Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
36205	T5	50	2.0	2.5	.098	110	4.3	.03	10
36210	T6	50	2.0	3.5	.139	125	4.9	.06	10
36212	T7	50	2.0	3.5	.139	125	4.9	.06	10
36215	T8	60	2.4	3.5	.139	135	5.3	.06	10
36220	T9	60	2.4	4.0	.157	140	5.5	.09	10
36225	T10	80	3.1	4.0	.157	170	6.7	.13	10
36230	T15	80	3.1	4.0	.157	170	6.7	.13	10
36235	T20	100	3.9	4.0	.157	200	7.9	.17	10
36240	T25	100	3.9	4.5	.177	200	7.9	.18	10
36245	T27	115	4.5	5.5	.216	215	8.5	.20	10
36250	T30	115	4.5	6.0	.236	225	8.9	.28	10

**Item No.** T6, T8, T10, T15, lbs. 36292 T20, T25, T27, T30 1.45



**36293 6 Pc. Set TORX®**  
**Item No.** T6, T7, T8, T9, lbs. 36293 T10, T15 .78


**Wiha TORX® Protturn Screwdrivers**

**protturn**  
**TORX®**

Through hardened for optimum wear resistance

Molded on ergonomic handle proportioned to blade sizes


High performance tool steel blades

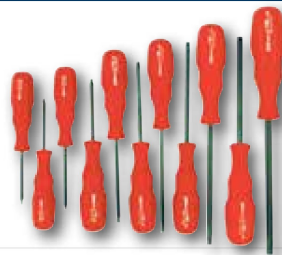

**45589 Set 11 Pcs. TORX®**  
**Item No. TORX® :**  
45589 T6, T7x50mm, T8, T9x60mm, lbs. T10, T15x80mm, T20, T25x100mm, 2.0 T27, T30x115mm, T40x130mm



**45591 Set 6 Pcs. TORX®**  
**Item TORX® :** lbs. 45591 T7, T8, T9, T10, T15, T20 .72

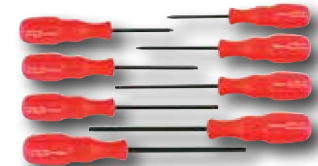


**45592 Set 8 Pcs. TORX®**  
**Item** lbs. 45592 T8, T9, T10, T15, T20, T25, T27, T30 1.10



**455 TORX® Screwdriver, With Wiha-Protturn Handle** Blade high alloy CVM steel, hardened, black finish. Molded on ergonomic Wiha-Protturn handle, impact resistant.



Item No.	Size	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
45505	T6	50	2.0	3.5	.139	129	5.1	.05	10
45506	T7	50	2.0	3.5	.139	129	5.1	.05	10
45511	T8	60	2.4	3.5	.139	139	5.5	.06	10
45516	T9	60	2.4	4.0	.157	149	5.8	.08	10
45521	T10	80	3.1	4.0	.157	170	6.7	.10	10
45522	T10	275	10.8	4.0	.157	363	14.2	.13	10
45526	T15	80	3.1	4.0	.157	170	6.7	.10	10
45531	T20	100	3.9	4.0	.157	190	7.5	.11	10
45536	T25	100	3.9	4.5	.177	190	7.5	.11	10
45541	T27	115	4.5	5.5	.216	215	8.4	.11	10
45546	T30	115	4.5	6.0	.236	215	8.4	.20	10
45551	T40	130	5.1	7.0	.275	240	9.4	.28	10
45561	T50	130	5.1	9.0	.354	240	9.4	.31	10

 Retainer out of stainless steel

**48400 1/4" Bit Holding Screwdriver, With Wiha Protturn Handle** Magnetic, holds bit and screw. Shaft CVM steel, nickel-plated. Handle, molded on, impact resistant.

Item No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
48400	1/4	125	5.0	243	9.6	.24	10

