



Wiha SoftFinish® Handle - Ergonomic Cushion Grip

Handle is molded directly onto the blade for a permanent bond



Wiha SoftFinish® Handle: Featuring advanced technology dual material molding. A remarkable improvement in handle design, comfort and performance. The SoftFinish® ergonomic shape allows maximum torque and user comfort.

Wiha Nut Drivers are precision formed to exact tolerances for a perfect fit every time

All blades are made of Wiha's exclusive formula chrome-vanadium-molybdenum tool steel, super hardened plated for unmatched durability



341 Nut Driver, With Wiha-SoftFinish® Handle Inch sizes. Blade CVM steel, hardened.

Deep drawn 1" socket. Solid shafts. Wiha-SoftFinish® handle, multi-component, cushion grips.


Item	⊙	—	—	—	—	—	—	↺	↻
No.	Inch	Inch	mm	mm	Inch	Inch	mm	lbs.	pkg.
34134	9/64	5.0	125	238	9.4	1.18	30	.18	10
34135	5/32	5.0	125	238	9.4	1.18	30	.24	10
34136	3/16	5.0	125	238	9.4	1.18	30	.25	10
34137	7/32	5.0	125	238	9.4	1.18	30	.26	10
34138	1/4	5.0	125	246	9.7	1.42	36	.38	10
34139	5/16	5.0	125	246	9.7	1.42	36	.40	10
34140	11/32	5.0	125	246	9.7	1.42	36	.40	10
34141	3/8	5.0	125	246	9.7	1.42	36	.40	10
34142	7/16	5.0	125	246	9.7	1.61	41	.40	10
34143	1/2	5.0	125	246	9.7	1.61	41	.40	10
34144	9/16	5.0	125	246	9.7	1.61	41	.40	10
34145	5/8	5.0	125	246	9.7	1.61	41	.40	10

341 Nut Driver, With Wiha-SoftFinish® Handle Metric sizes

Item	⊙	—	—	—	—	—	—	↺	↻
No.	mm	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
34120	5.0	125	5.0	238	9.4	30	1.18	.14	10
34121	5.5	125	5.0	238	9.4	30	1.18	.14	10
34122	6.0	125	5.0	238	9.4	30	1.18	.15	10
34123	7.0	125	5.0	238	9.4	36	1.42	.25	10
34124	8.0	125	5.0	238	9.4	36	1.42	.25	10
34126	10.0	125	5.0	238	9.4	36	1.42	.27	10
34127	11.0	125	5.0	247	9.7	41	1.61	.37	10
34128	12.0	125	5.0	247	9.7	41	1.61	.40	10
34129	13.0	125	5.0	247	9.7	41	1.61	.40	10
34130	14.0	125	5.0	247	9.7	41	1.61	.40	10
34131	15.0	125	5.0	247	9.7	41	1.61	.40	10
34132	16.0	125	5.0	249	9.8	41	1.61	.42	10
34133	17.0	125	5.0	249	9.8	41	1.61	.42	10

341 Magnetic Nut Driver, With Wiha-SoftFinish® Handle

Item	⊙	—	—	—	—	↺	↻
No.	mm	mm	Inch	mm	Inch	lbs.	pkg.
34152	5.5	125	5.0	238	9.4	.14	10
34154	5.5	250	9.8	361	14.2	.21	10
34158	7.0	125	5.0	238	9.4	.15	10

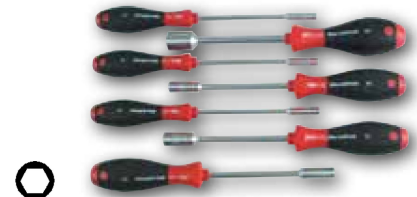

34193 7 Pcs. Nut Driver Set Inch sizes.

Blade CVM steel, hardened.

Deep drawn 1" socket.

Item	⊙	—	⊙	—	↺
No.	Inch	Inch	Inch	Inch	lbs.
34193	3/16	5.0	3/8	5.0	1.89
	1/4	5.0	7/16	5.0	
	5/16	5.0	1/2	5.0	
	11/32	5.0			



34195 10 Piece Nut Driver Set Inch sizes

Item	⊙	—	⊙	—	↺
No.	Inch	Inch	Inch	Inch	lbs.
34195	3/16	5.0	3/8	5.0	3.12
	7/32	5.0	7/16	5.0	
	1/4	5.0	1/2	5.0	
	5/16	5.0	9/16	5.0	
	11/32	5.0	5/8	5.0	



34194 7 Piece Nut Driver Set Metric sizes

Item	⊙	—	⊙	—	↺
No.	mm	mm	mm	mm	lbs.
34194	5.0	125	8.0	125	1.93
	5.5	125	10.0	125	
	6.0	125	13.0	125	
	7.0	125			