


The TORXPlus® Advantage

The TorxPlus® Drive System offers 100% improvement in driver bit fatigue & 25% average improvement in driver bit torsional strength. In addition its unique design provides optimum torque transfer & eliminates the need for excessive end load pressure while driving the fastener. The TorxPlus® configuration also virtually eliminates tool "camout" & slippage that can damage the head of the fastener and cause reduced tool life.

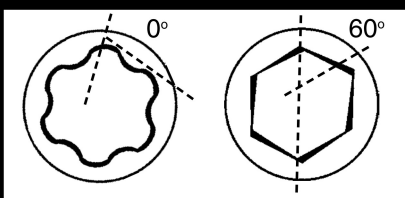


Not for use in standard Torx fasteners

- Broad Surface For Driving
- Features 0° Drive Angle Between The Fastener & Driver
- Greater Engagement Depth




Wiha PocketStar Fold Out



 Push button key release

36697 TORXPlus® PocketStar Fold

Outs, 8 Pc. Set High alloy CVM steel, hardened, molded ergonomic handle.

Item No.  lbs.


TORXPlus® PocketStar lbs. .31

36697 : IP6, IP7, IP8, IP9,

IP10, IP15, IP20, IP25

Wiha TORXPlus® Tools 2 Packs & 10 Packs

TORXPlus®

 Not for use in standard Torx fasteners


370 TORXPlus® Screwdriver, With Flag Handle - 2 & 10 Packs

Ideal for use with indexable carbide tooling and also for working in confined spaces. Blade high alloy CVM steel, hardened, black finish. Flag handle high quality plastic, impact resistant.

| Item No. | Size | mm | Inch | mm | Inch | mm | Inch | lbs. | pkg. |
|----------|------|----|------|----|------|------|------|------|------|
| 37063 | IP5 | 35 | 1.4 | 63 | 2.6 | 15.0 | .75 | .01 | 10 |
| 37064 | IP6 | 35 | 1.4 | 63 | 2.6 | 15.0 | .75 | .01 | 10 |
| 37065 | IP7 | 35 | 1.4 | 67 | 2.6 | 19.0 | .75 | .01 | 10 |
| 37066 | IP8 | 40 | 1.6 | 72 | 2.8 | 19.0 | .75 | .01 | 10 |
| 37067 | IP9 | 40 | 1.6 | 74 | 2.9 | 23.5 | .93 | .01 | 10 |
| 37068 | IP10 | 40 | 1.6 | 74 | 2.9 | 23.5 | .93 | .01 | 10 |
| 37069 | IP15 | 45 | 1.8 | 80 | 3.1 | 28.0 | 1.10 | .02 | 10 |
| 37070 | IP20 | 45 | 1.8 | 80 | 3.1 | 28.0 | 1.10 | .02 | 10 |



37092 Flag Handle TORXPlus® Set, 7 Pc. in Metal Stand

Set includes:  lbs. .31

IP6, IP7, IP8, IP9, IP10, IP15, IP20




36592 TORXPlus® 7 Pc. Wing Handle

Set In Metal Stand. Equipped with IP6, IP7, IP8, IP9, IP10, IP15, IP20

| Item No. | lbs. | pkg. |
|----------|------|------|
| 36592 | .38 | 1 |

TORXPlus®

 Not for use in standard Torx fasteners

365 TORXPlus® Screwdriver, With Wing Handle - 2 & 10 Packs

Blade high alloy CVM steel, hardened, black finish. Wing handle high quality plastic, impact resistant.

| Item No. | Size | mm | Inch | mm | Inch | mm | Inch | lbs. | pkg. |
|----------|------|----|------|----|------|----|------|------|------|
| 36539 | IP5 | 35 | 1.4 | 70 | 2.7 | 40 | 1.6 | .02 | 10 |
| 36541 | IP6 | 35 | 1.4 | 70 | 2.7 | 40 | 1.6 | .02 | 10 |
| 36543 | IP7 | 35 | 1.4 | 70 | 2.7 | 40 | 1.6 | .02 | 10 |
| 36545 | IP8 | 40 | 1.6 | 75 | 3.0 | 40 | 1.6 | .02 | 10 |
| 36547 | IP9 | 40 | 1.6 | 75 | 3.0 | 40 | 1.6 | .02 | 10 |
| 36549 | IP10 | 40 | 1.6 | 75 | 3.0 | 40 | 1.6 | .02 | 10 |
| 36551 | IP15 | 45 | 1.8 | 80 | 3.1 | 40 | 1.6 | .02 | 10 |
| 36553 | IP20 | 45 | 1.8 | 80 | 3.1 | 40 | 1.6 | .02 | 10 |



| Item No. | Size | pkg. |
|----------|------|------|
| 36524 | IP5 | 2 |
| 36526 | IP6 | 2 |
| 36527 | IP7 | 2 |
| 36528 | IP8 | 2 |
| 36529 | IP9 | 2 |
| 36531 | IP10 | 2 |
| 36532 | IP15 | 2 |
| 36533 | IP20 | 2 |