



NIDEC-SHIMPO CORPORATION  
INSTRUMENTS DIVISION

MPN	Description
FG-M10CLV10U	Clevis Grip, M10 Thread, 500 lb (250 Kg) Capacity



NIDEC-SHIMPO's Clevis Grip easily attach and secure odd shaped parts, punched samples or tension springs. Concave shape of pins assures centering under load. Throat clearance with pin is 0.5" (12.7 mm) and can easily accept samples up to 0.375" (9.65 mm) wide.

Grips and attachments sold individually (not in pairs).


## Features

NIDEC-SHIMPO's Clevis Grip easily attach's and secures odd shaped parts, punched samples or tension springs. Concave shape of pins assures centering under load. Throat clearance with pin is 0.5" (12.7 mm) and can easily accept samples up to 0.375" (9.65 mm) wide.

 
## Specifications

Throat Clearance	0.5" (12.7 mm) with pin
Samples Width	0.375" (9.65 mm) wide
Capacity	500 lb (250 Kg)

## Dimensions

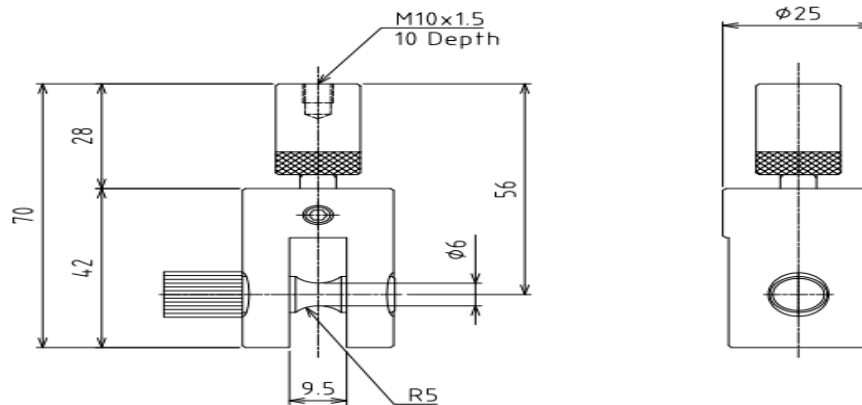

Weight: Approx. 130g

DIMENSION		TOLERANCE	APPROVED	UNITS	PARTS NAME
TO 6		±0.1	Toshi	mm	CLEVIS GRIP (UPPER)
OVER 6 TO 30	±0.2				
OVER 30 TO 120	±0.3				
OVER 120 TO 400	±0.5				
OVER 400 TO 1000	±0.8		CHECKED	MATERIAL	
OVER 1000 TO 2000	±1.2		MO	-	
OVER 2000 TO 4000	±2.0		DRAWN	QUANTITY	MODEL
HEAT TREATMENT / HARDNESS				1	FG-M10CLV10U
				SCALE	
SURFACE TREATMENT			2 : 1		CODE
			DATE 04/29/2016		EJ450065
			<b>NIDEC-SHIMPO AMERICA CORP</b>		DRAWING NO.
			Itasca, IL 60143, USA Tel: (630)924-7138		