

Film Grip



SHIMPO's Film Grip attachments are heavy-duty, spring-loaded grips with serrated jaws which are ideal for handling film samples up to 0.39" (10 mm) thick and 0.79" (20 mm) or 1.97" (50 mm) wide.

Grips and attachments sold individually (not in pairs).


Features

NIDEC-SHIMPO's Film Grip attachments are heavy-duty, spring-loaded grips with serrated jaws which are ideal for handling film samples up to 0.39" (10 mm) thick and 0.79" (20 mm) or 1.97" (50 mm) wide.


Specifications


Model	FG-M6FLM20	FG-M6FLM50U
Range Thickness	0.079" (2 mm)	0.079" (2 mm)
Width	0.8" (20 mm)	1.97" (50 mm)
Capacity	100 lb (50 Kg)	100 lb (50 Kg)

Dimensions

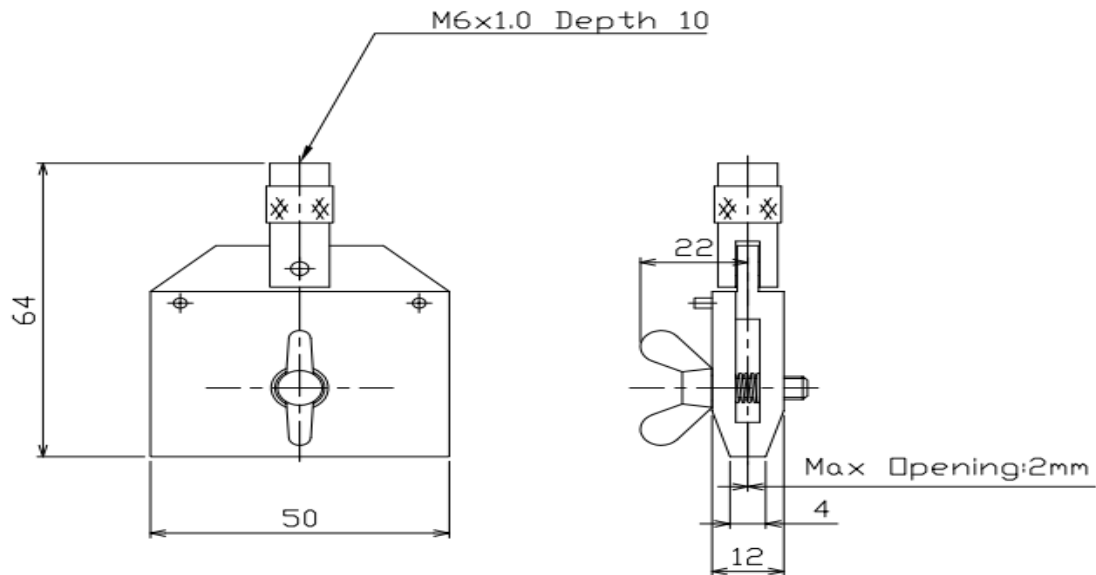


Weight: Approx. 150g

DIMENSION		TOLERANCE	APPROVED	UNITS	PARTS NAME
TO 6		±0.1	Toshi	mm	FILM GRIP (UPPER)
OVER 6 TO 30		±0.2	CHECKED	MATERIAL	
OVER 30 TO 120		±0.3	MO	-	MODEL
OVER 120 TO 400		±0.5	DRAWN	QUANTITY	
OVER 400 TO 1000		±0.8	Kei	1	FG-M6FLM50U
OVER 1000 TO 2000		±1.2		SCALE	
OVER 2000 TO 4000		±2.0		1 : 1	CODE
HEAT TREATMENT / HARDNESS			DATE 01/29/2016		EJ450058
SURFACE TREATMENT			NIDEC-SHIMPO AMERICA CORP Itasca, IL 60143, USA Tel: (630)924-7138		DRAWING NO.
					BGBM018

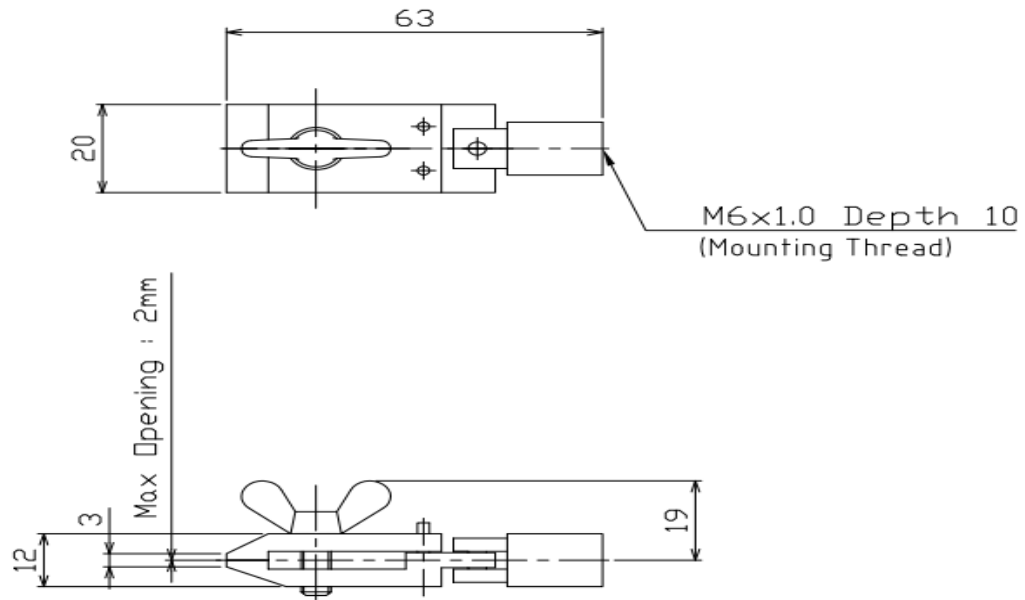

Weight: Approx. 75g

 DIMENSION		TOLERANCE	APPROVED	UNITS	PARTS NAME
TO 6		±0.1	Toshi	mm	FILM GRIP M6
OVER 6 TO 30		±0.2			
OVER 30 TO 120		±0.3			
OVER 120 TO 400		±0.5			
OVER 400 TO 1000		±0.8	MO	MATERIAL	MODEL FG-M6FLM20
OVER 1000 TO 2000		±1.2	Kei	QUANTITY	
OVER 2000 TO 4000		±2.0		1	
HEAT TREATMENT / HARDNESS				SCALE	
				1 : 1	
SURFACE TREATMENT			DATE 01/29/2016		DRAWING NO. BGBM021
			NIDEC-SHIMPO AMERICA CORP Itasca, IL 60143, USA Tel: (630)924-7138		