



NIDEC-SHIMPO CORPORATION  
INSTRUMENTS DIVISION

MPN	Description
FG-M6JAC5U	Jacobs Chuck Grip, M6 Thread, 100 lb (50 kg) Capacity



Jacob's Chuck Grip attachments are designed for testing low gauge wire and rigid rods. The Chuck Grip accepts material diameters from 0.02" (0.05 mm) to 0.20" (5 mm).

Grips and attachments sold individually (not in pairs).


## Features

NIDEC-SHIMPOS's Jacob's Chuck Grip attachments are designed for testing low gauge wire and rigid rods. The Chuck Grip accepts material diameters from 0.02" (0.05 mm) to 0.20" (5 mm).

 
## Specifications

Material Diameters	0.02" (.05 mm) to .20" (5 mm)
Capacity	100 lb (50 kg)

## Dimensions

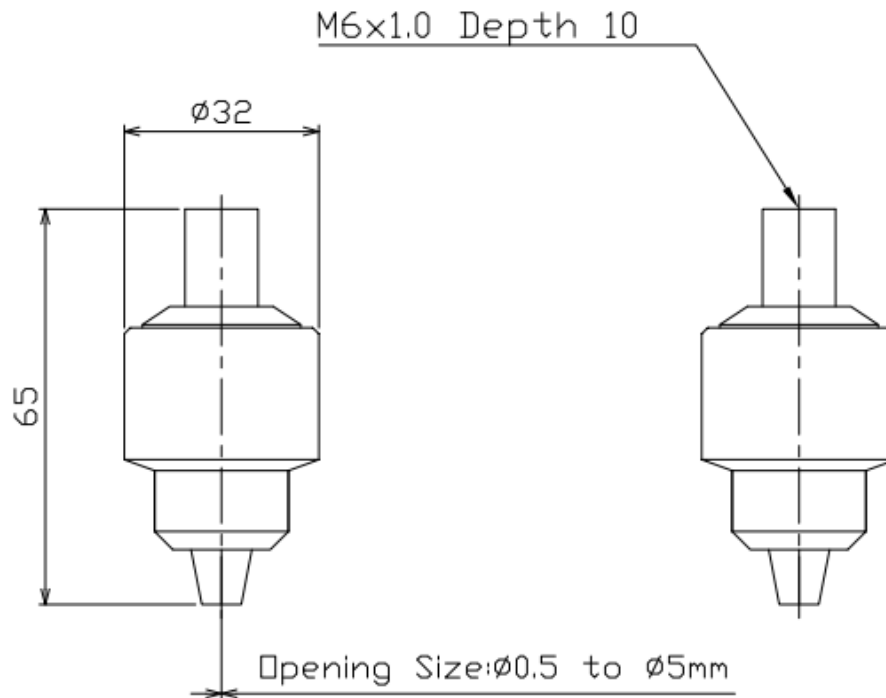

Weight: Approx. 160g

DIMENSION	TOLERANCE	APPROVED	UNITS	PARTS NAME
TO 6	±0.1	Toshi	mm	JACOB'S GRIP (UPPER)
OVER 6 TO 30	±0.2	CHECKED	MATERIAL	
OVER 30 TO 120	±0.3	MO	-	MODEL
OVER 120 TO 400	±0.5	DRAWN	QUANTITY	
OVER 400 TO 1000	±0.8	Kei	1	FG-M6JAC5U
OVER 1000 TO 2000	±1.2		SCALE	CODE
OVER 2000 TO 4000	±2.0		1 : 1	
HEAT TREATMENT / HARDNESS		DATE	02/02/2016	EJ450060
SURFACE TREATMENT		<b>NIDEC-SHIMPO AMERICA CORP</b> Itasca, IL 60143, USA Tel: (630)924-7138		DRAWING NO.
				BGBM034