



NIDEC-SHIMPO CORPORATION  
INSTRUMENTS DIVISION

MPN	Description
FG-M6FTG20U	Flat Tensile Grip, M6 Thread, 100 lb (50 kg) Capacity



NIDEC-SHIMPO's Flat Chuck Tensile Grip attachments possess a 0.79" (20 mm) square, serrated gripping face that can accept samples up to 0.75" (19 mm) thick.

Grips and attachments sold individually (not in pairs).


## Features

NIDEC-SHIMPO's Flat Chuck Tensile Grip attachments possess a 0.79" (20 mm) square, serrated gripping face that can accept samples up to 0.75" (19 mm) thick.


 
## Specifications

Material Thickness	0.75" (19 mm)
Capacity	100 lb (50 kg)

## Dimensions

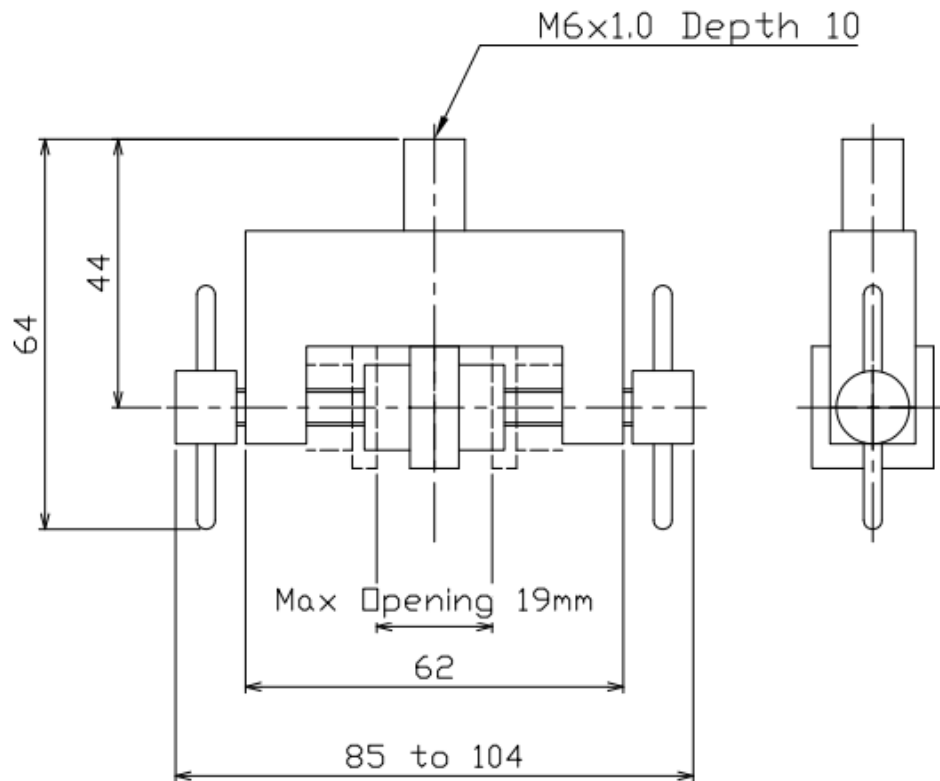

Weight: Approx. 180g

DIMENSION		TOLERANCE	APPROVED	UNITS	PARTS NAME
TO 6		±0.1	Toshi	mm	FLAT GRIP (UPPER)
OVER 6 TO 30	±0.2				
OVER 30 TO 120	±0.3				
OVER 120 TO 400	±0.5				
OVER 400 TO 1000	±0.8		CHECKED	MATERIAL	
OVER 1000 TO 2000	±1.2		MO	-	
OVER 2000 TO 4000	±2.0		DRAWN	QUANTITY	MODEL
HEAT TREATMENT / HARDNESS				1	FG-M6FTG20U
				SCALE	
SURFACE TREATMENT				1 : 1	CODE
				DATE 01/29/2016	EJ450059
			<b>NIDEC-SHIMPO AMERICA CORP</b> Itasca, IL 60143, USA Tel: (630)924-7138	DRAWING NO.	BGBM022