


97 32 240





Crimping Pliers

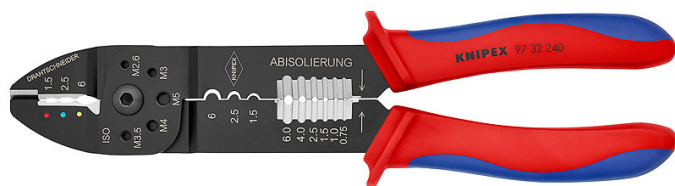

- For cutting cables, stripping wire and crimping insulated and non-insulated terminals, connectors and plug type connectors
- With threaded holes for cutting copper and brass screws threaded M 2.6 / M 3 / M 3.5 / M 4 and M 5
- Bolted joint for higher stability and even movement
- Special steel, high-strength



Article No.	97 32 240
EAN	4003773079491
Pliers	black lacquered
Handles	with multi-component grips
Applications	insulated terminals + cable connectors
	non-insulated terminals + cable connectors
Capacity in square millimetres mm²	0,5 - 6,0
	0,5 - 6,0 mm ²
Number of crimping positions	3
	3
AWG	20 - 10
	20 - 10
Length mm	240
Net weight g	300

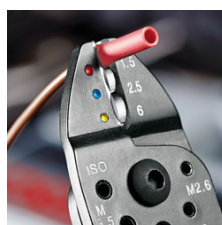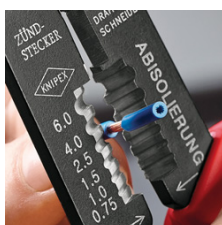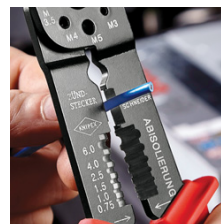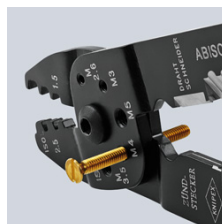

technical change and errors excepted