

Start Spot IP65

START SPOT LED IP65 3000K G2

0053545



Product features

- Integrated LED IP65 fixed downlight, RAL9016, 475LM, 6.5W, 3000K, 100 degree beam angle, polycarbonate white body, low profile 58mm recessed depth, 86mm bezel diameter, 68-74mm cutout, frosted lens.



PRODUCT OVERVIEW

Product code	0053545
Product name	START SPOT LED IP65 3000K G2
Technology	LED
Type	LED
Housing material	Polycarbonate
Mount	Ceiling recessed
General application	Residential & Consumer
Certifications	EUNEW001
ETIM Class	EC001702
E-number Finland	4170526
E-number Sweden	7467947
Fixture luminous flux (lm)	475
Luminaire efficacy (lm/W)	73
LOR (%)	100
Colour temperature (K)	3000
Light colour	Warm white
Beam Angle (°)	100
Photobiological Risk Group	RG0
Total power consumption (W)	7
Electrical protection	Class II
Average life (Nominal) (h)	30000
Housing colour	White
IP rating	IP65
IK rating	IK03
Product EAN number	5410288535456
Lamps	No
Included lamp	INTEGRATED LED

Start Spot IP65

START SPOT LED IP65 3000K G2

0053545

DATA TABLE

General data

Product code	0053545
Product name	START SPOT LED IP65 3000K G2
Technology	LED
Type	LED
Housing material	Polycarbonate
Mount	Ceiling recessed
General application	Residential & Consumer
Certifications	EUNEW001
ETIM Class	EC001702
E-number Finland	4170526
E-number Sweden	7467947

Optical data

Fixture luminous flux (lm)	475
Luminaire efficacy (lm/W)	73
LOR (%)	100
Colour temperature (K)	3000
Correlated colour temperature range (K)	3000
Light colour	Warm white
Adjustable chromaticity	N
Beam Angle (°)	100
Distribution type	Direct
Photobiological Risk Group	RG0

Electrical data

Total power consumption (W)	7
Mains voltage (V)	220-240V~
Electrical protection	Class II
Transformer required	Yes
Nominal Frequency (Hz)	50/60Hz

Lifetime data

Lumen maintenance - L70 B50	25000
Average life (Nominal) (h)	30000

Physical data

Housing colour	White
IP rating	IP65
IK rating	IK03

Start Spot IP65

START SPOT LED IP65 3000K G2


0053545

Diffuser material	Acrylic
Reflector finish	Frosted
Nominal Product Length (mm)	86
Nominal Product Width (mm)	86
Nominal Product Height (mm)	60
Weight (kg)	0.076
Recessed Depth (mm)	58

Packaging

Single packaging type	Carton
Product EAN number	5410288535456
Packaging single length (cm)	9.0
Packaging single width (cm)	7.5
Packaging single height (cm)	9.0
DUN14 (inner)	25410288535450
Units per inner package	6
Packaging inner length (cm)	19.0
Packaging inner width (cm)	9.0
Packaging inner height (cm)	28.5
DUN14 (outer)	15410288535453
Units per outer package	48
Packaging outer length (cm)	38.0
Packaging outer width (cm)	30.0
Packaging outer height (cm)	40.5

PHOTOMETRY

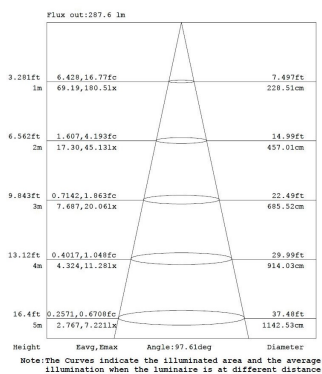

TECHNICAL DRAWINGS



Start Spot IP65

START SPOT LED IP65 3000K G2

0053545

