

SylCircle

SYLCIRCLE 18W 1300LM 4000K

0043262



Range Features

-

PRODUCT OVERVIEW

Certifications	CE
Colour temperature (K)	4000
Colour	White
CRI (Ra)	80
Dimmable	Non-dim / not dimmable (switched only)
EAN code	5410288432625
Luminous flux (lm)	1300
Housing	Aluminium
IK rating	IK03
IP rating	IP44
Light colour	Neutral white
LOR (%)	100
Mount	Surface
Ordering number	0043262
Efficacy (Rated) (lm/w)	72.22
Average life (Rated) (h)	30000
Technology	LED
Voltage (V)	220-240
Included lamp	Integrated LED
Compatible with bulbs of energy class:	A++ A+ A
Colour consistency (SDCM)	5 SDCM
Photobiological Risk Group	Group 0 (exempt)

DATA TABLE

General data

Certifications	CE
Control gear type	Electronic
Dimmable	Non-dim / not dimmable (switched only)
EAN code	5410288432625

SylCircle

SYLCIRCLE 18W 1300LM 4000K

0043262

Environment	Internal
Fixture rating	Closed
General application	Residential & Consumer
Housing	Aluminium
Mount	Surface
Ordering number	0043262
Product name	SYLCIRCLE 18W 1300LM 4000K
Average life (Rated) (h)	30000
Technology	LED
Compatible with bulbs of energy class:	A++ A+ A
Product features	<p>Ceiling / wall luminaire with integrated LED</p> <p>Perfect solution for hallways, kitchens or applicable zone 2 bathroom and wet areas thanks to its IP44 rating</p> <p>Even and uniform light distribution with a halo lighting effect on the wall surface</p> <p>18W</p> <p>1300 lumens</p> <p>Supplied with LED driver (non-dimmable)</p> <p>IK03 PMMA diffuser</p> <p>Low maintenance with 30,000 hours LED life expectancy</p>

Optical data

Colour temperature (K)	4000
CRI (Ra)	80
Distribution type	Direct
Luminous flux (lm)	1300
Light colour	Neutral white
LOR (%)	100
Colour consistency (SDCM)	5 SDCM
Photobiological Risk Group	Group 0 (exempt)

Physical data

Colour	White
Diffuser finish	Opal
Diffuser material	PMMA
Height (mm)	95
IK rating	IK03
IP rating	IP44
Lamp included	Integrated
Length (mm)	340
Reflector finish	Diffuser
Weight (kg)	0.5
Width (mm)	340
Included lamp	Integrated LED


SylCircle

SYLCIRCLE 18W 1300LM 4000K

0043262

Electrical data

Drive current (mA)	270
Electrical protection	Class I
Glow wire test	650
Efficacy (Rated) (lm/w)	72.22
Total power consumption (W)	18
Voltage (V)	220-240

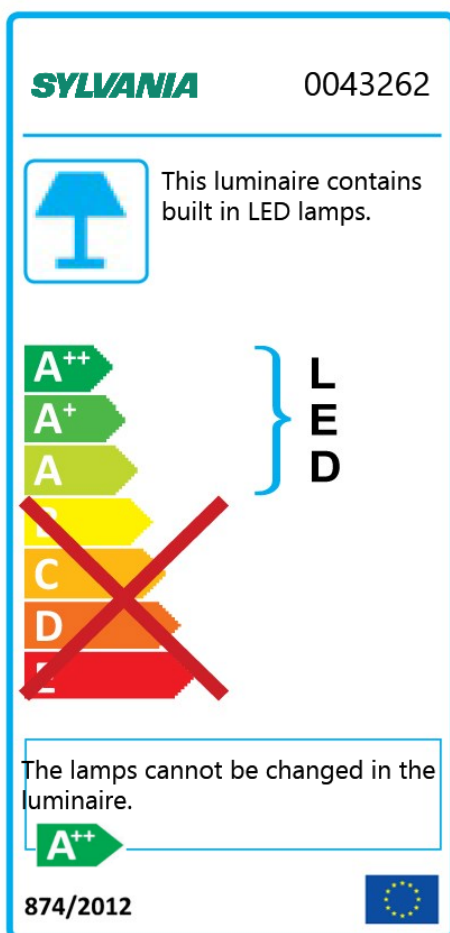

SylCircle

SYLCIRCLE 18W 1300LM 4000K

0043262

