

ToLEDo GLS

ToLEDo GLS V3 810LM 827 E27 SL

0026672



Range Features

- Wide beam angle of 220 degrees! Instant start Long lifetime 15,000 hours Short payback period Up to 85% energy savings compared to incandescent equivalent



PRODUCT OVERVIEW

Lamp finish	Frosted
Lamp shape	A60
Colour temperature (K)	2700
Colour	Homelight
CRI (Ra)	80
Dimmable	No
EAN code	5410288266725
Energy class	A+
Equivalent watt (W)	60
Cap/Base	E27
Type	ToLEDo GLS
Watt (Nominal) (W)	10
Light colour	827 Homelight
Ordering number	0026672
Efficacy (Rated) (lm/w)	81
Average life (Rated) (h)	15000
Luminous flux (Rated) (lm)	810
Technology	LED
Voltage (V)	220-240
Colour consistency (SDCM)	6

DATA TABLE

General data

Average life (Nominal) (h)	15000
Control gear required	No
Lamp finish	Frosted
Lamp shape	A60
Control gear availability	No

ToLEDo GLS

ToLEDo GLS V3 810LM 827 E27 SL

0026672

Dimmable	No
Dry applications use only	Yes
EAN code	5410288266725
Energy class	A+
Energy saving lamp	Yes
General application	Hospitality; Residential & Consumer
Intended purpose	No
Cap/Base	E27
Lamp mercury content (mg)	0
Type	ToLEDo GLS
No. of switching cycles before premature failure (min)	> 50,000
Optimal operating condition (°C)	25
Ordering number	0026672
Range features	Wide beam angle of 220 degrees! Instant start Long lifetime 15,000 hours Short payback period Up to 85% energy savings compared to incandescent equivalent
Product name	ToLEDo GLS V3 810LM 827 E27 SL
Average life (Rated) (h)	15000
Special purpose lamp	No
Starting time (max) (s)	0.05
Technology	LED
Transformer required	No
Warm-up time to 60% of full light (max) (s)	< 1s => 60%
E-number FI	4740291

Optical data

Colour temperature (K)	2700
CRI (Ra)	80
Light colour	827 Homelight
Lumen maintenance at end of nominal life (%)	70
Luminous flux (Nominal) (lm)	810
Luminous flux (Rated) (lm)	810
Suitable for accent lighting	No
Adjustable chromaticity	No
Colour consistency (SDCM)	6

Physical data

Colour	Homelight
Diameter (mm)	60
Max. Lamp Diameter (mm) - D	60
Lamp Length (mm) - C/L	109

ToLEDo GLS

ToLEDo GLS V3 810LM 827 E27 SL


0026672

Lamp dimension equal to filament lamp equivalent	Yes
---	-----

Electrical data

Current (A)	42
Drive current (mA)	79
Equivalent watt (W)	60
kWh per 1000 hours burning time	10
Lamp power factor	0.5
Watt (Nominal) (W)	10
Efficacy (Rated) (lm/w)	81
Watt (Rated) (W)	10
Voltage (V)	220-240

TECHNICAL DRAWINGS

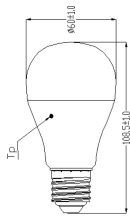

ToLEDo GLS

ToLEDo GLS V3 810LM 827 E27 SL

0026672

