


# Gecko with Latches Connectors


GECKO WITH LATCHES

## Male Horizontal PC Tail - Latched


- Secure fixing to the PCB via retention bars for through hole.
- Surface mount option for automated assembly.
- Easy-to-release latches - tooling available for additional assistance with releasing latches - see part numbers **Z125-926xx00**.
- 2A current capacity, resists high vibration and shock.
- Withstands extremes of temperature: -65°C to +150°C.

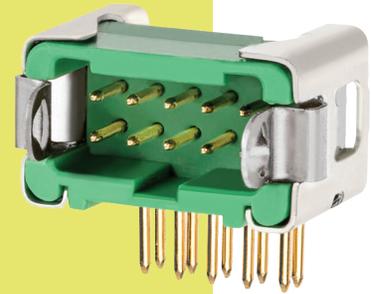

### PC TAIL LATCH

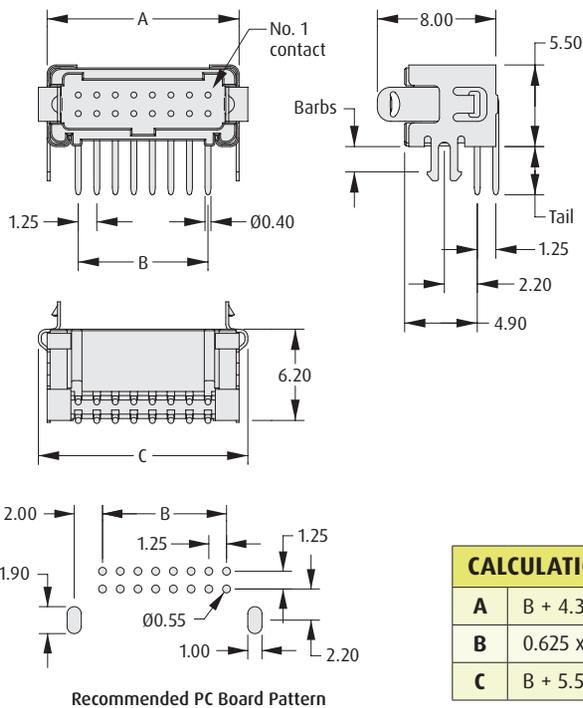

### SURFACE MOUNT LATCH

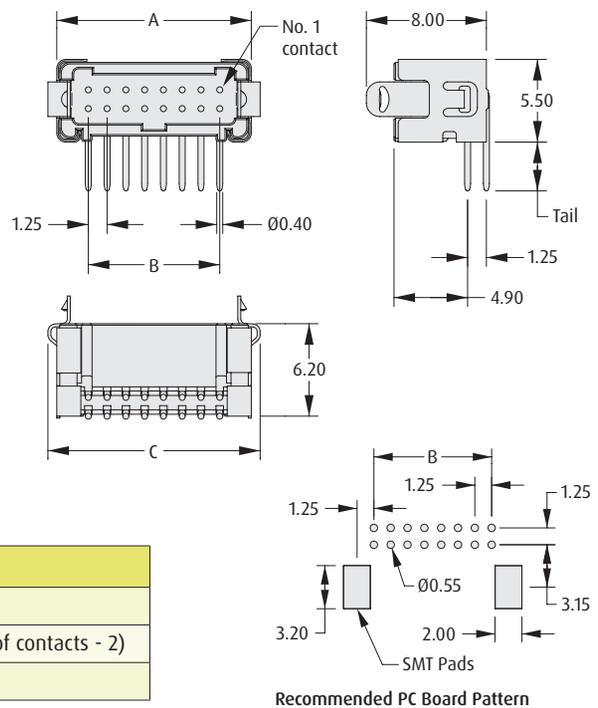

CALCULATION	
<b>A</b>	B + 4.3
<b>B</b>	0.625 x (Total No. of contacts - 2)
<b>C</b>	B + 5.5

### HOW TO ORDER

**G125 - M HX XX 05 LX X**

**SERIES CODE**

**TYPE**

<b>H1</b>	3.3mm PC Tail
<b>H2</b>	4.8mm PC Tail

**TOTAL NO. OF CONTACTS**

06, 10, 12, 16, 20, 26, 34, 50

**PACKAGING**

<b>R</b>	Tape & Reeled
<b>P</b>	Loose

**LATCH**

<b>L1</b>	Barbs for 3.3mm PC Tail
<b>L2</b>	Barbs for 4.8mm PC Tail
<b>L3</b>	Surface Mount Latch

**FINISH**

<b>05</b>	Gold
-----------	------

All dimensions in mm.

Patent Published