

Connector - PRC 5-FC-FS6 8-21 - 1410656


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



PRC connector, black, 5-pos., 1.5 mm² ... 6 mm²/690 V/35 A, with screw connection for cables with an outside diameter of 8 mm ... 21 mm.

RoHS

Key Commercial Data

Packing unit	1 STK
GTIN	 4 046356 904247
GTIN	4046356904247
Weight per Piece (excluding packing)	101.600 g
Custom tariff number	85366990
Country of origin	Germany
Note	Made to Order (non-returnable)

Technical data

General data

Number of positions	5
Protection class	II
Color	black
Locking type	Snap-in locking
Insertion/withdrawal cycles	100
Pull-out-force	175 N ± 50 N
Insertion force	40 N ± 10 N
Degree of protection (when plugged in)	IP66 / IP68 (2m / 24h) / IP69K

Connection data

Rated current	30 A (with 6 mm ² conductor cross section)
Rated voltage (III/2)	690 V
Conductor cross section flexible min.	1.5 mm ²
Conductor cross section flexible max.	6 mm ²

Connector - PRC 5-FC-FS6 8-21 - 1410656

Technical data

Connection data

Conductor cross section solid min.	1.5 mm ²
Conductor cross section solid max.	6 mm ²
Stripping length	12 mm
Torque	1 Nm
Type of contact	Socket
Stripping length of the sheath	50 mm

Material data

Contact material	Cu
Contact surface material	silver-plated
Contact carrier material	mPPE
Material of grip body	mPPE
Flammability rating according to UL 94	V0

Standards and Regulations


Flammability rating according to UL 94	V0
--	----

Environmental Product Compliance


China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Diagram

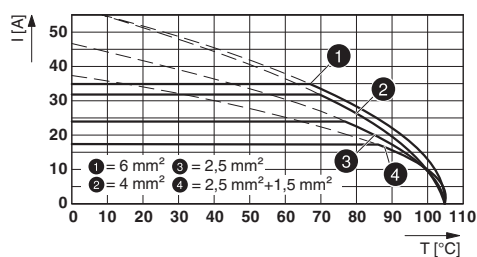


Dimensional drawing

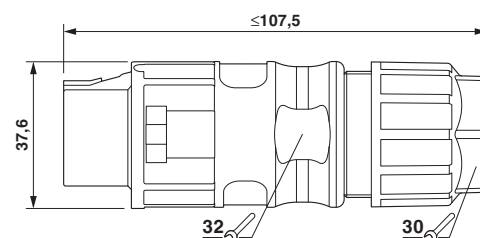


Connector - PRC 5-FC-FS6 8-21 - 1410656

Schematic diagram

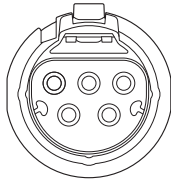

Schematic diagram

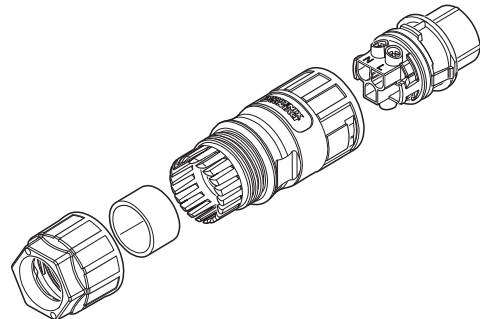

Connector pin assignment

Schematic design

Classifications

eCl@ss

eCl@ss 5.1	27143423
eCl@ss 6.0	27279220
eCl@ss 8.0	27440102
eCl@ss 9.0	27440103

ETIM

ETIM 4.0	EC002641
ETIM 5.0	EC002635
ETIM 6.0	EC002061

UNSPSC

UNSPSC 13.2	39121413
-------------	----------

Approvals

Approvals

Approvals


EAC / UL Listed / cUL Listed / null / null / null / cULus Listed


Ex Approvals


Approval details

Connector - PRC 5-FC-FS6 8-21 - 1410656

Approvals

EAC		B.01742
-----	---	---------

UL Listed		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm E221474-20150513
mm ² /AWG/kcmil	14-10	
Nominal current I _N	30 A	
Nominal voltage U _N	600 V	

cUL Listed		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm E221474-20150513
mm ² /AWG/kcmil	14-10	
Nominal current I _N	30 A	
Nominal voltage U _N	600 V	

	R 60117908	
mm ² /AWG/kcmil	6	
Nominal current I _N	21.4 A	
Nominal voltage U _N	500 V	

	R 60117904-0002	
mm ² /AWG/kcmil	6	
Nominal current I _N	35 A	
Nominal voltage U _N	690 V	

	R 60117904-0001	
mm ² /AWG/kcmil	6	
Nominal current I _N	32 A	
Nominal voltage U _N	500 V	

cULus Listed		
--------------	---	--

Connector - PRC 5-FC-FS6 8-21 - 1410656

Accessories

Accessories

Circular connector (cable-side)

Protective cap - PRC COVER F - 1409236



Protective cap for 3 and 5-pos. PRC field plugs

Screwdriver tools

Screwdriver - SZF 1-0,6X3,5 - 1204517



Actuation tool, for ST terminal blocks, also suitable for use as a bladed screwdriver, size: 0.6 x 3.5 x 100 mm, 2-component grip, with non-slip grip

Screwdriver - SZF 0-0,4X2,5 - 1204504



Actuation tool, for ST terminal blocks, also suitable for use as a bladed screwdriver, size: 0.4 x 2.5 x 75 mm, 2-component grip, with non-slip grip

Philips screwdriver - SF-PH 1-80 S-VDE - 1212693



Screwdriver, crosshead PH (lasered), insulated, size: PH 1 x 80, 2-component handle, with non-slip grip
