


ECatalog (?Cid=Root) / Power Transmission (?Cid=Power_Transmission)
/ Rod Ends & Linkages (?Cid=Rod_Ends_And_Linkages)
/ Ball & Socket Joints (?Cid=Ball_And_Socket_Joints)

Search Products...

Search

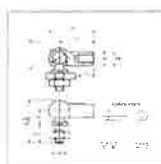

373.06.C

Steel Ball and Socket Joints Materials: Housing: Mild steel, zinc plated and clear passivated
Ball: Induction hardened

Enter Quantity

Request Quote

Metric

English

Specifications

Size	6
L1	32.5
L2	0.98 (in)
L3	0.45 (in)
L4	1.18 (in)
L5	0.49 (in)
L6	0.43 (in)
L7	0.30 (in)
Material Type	Steel
Thread Direction	RH
Ball Diameter (d1)	0.4 (in)
Thread (d2)	M6
D4	0.4 (in)
Spanner Flats A/F	0.3 (in)
Max Static Push/Pull	70 (kp)

Contact Us

Huco

Merchant Drive, Hertford

Hertfordshire, SG13 7BL - England

Phone: +44(0)1992 501900

Fax: +44 (0)1992 509890

Email: sales@huco.com (mailto:sales@huco.com)

Quick Links

[Design Guide \(/design-guide/overview\)](/design-guide/overview)

[ISO Certificate \(/-/media/Files/Literature/Brand/huco-](/-/media/Files/Literature/Brand/huco-dynatork/certificates/huco_iso_certification.ashx?)
[dynatork/certificates/huco_iso_certification.ashx?](/-/media/Files/Literature/Brand/huco-dynatork/certificates/huco_iso_certification.ashx?)

[la=en&hash=1173234EB4BA08092008B9DA9B8774EFFFEE919F\)](la=en&hash=1173234EB4BA08092008B9DA9B8774EFFFEE919F)

[Facility Locations \(http://www.altramotion.com\)](http://www.altramotion.com)

[Literature \(http://www.altraliterature.com/brands.asp?brandid=8\)](http://www.altraliterature.com/brands.asp?brandid=8)

Media

Facility Locations (<http://www.altramotion.com>)

Distributor Locator (</distributor-locator>)

Follow Us At

2018 © Altra Industrial Motion Corp. ALL Rights Reserved. Literature (<http://www.altraliterature.com/brands.asp?brandid=8>) | SiteMap (</sitemap>) | Inquiry (</contact/inquiry>)

(/)



