



RoHS Compliant

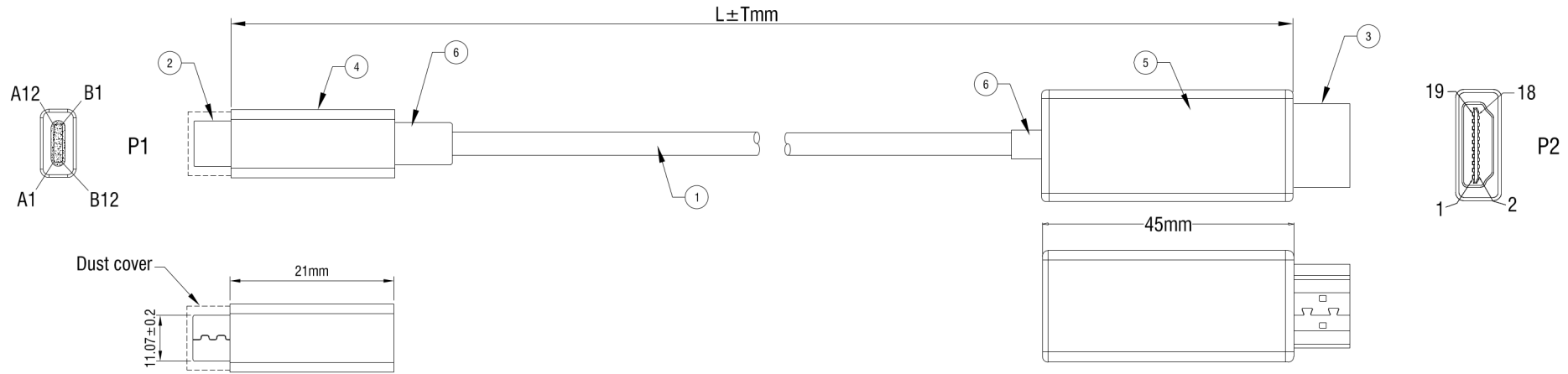

ITEM NO.	LENGTH	TOLERANCE	QBAG(mm)
USB3C-HDMI-1M	1000mm	30mm	0.1*180*220
USB3C-HDMI-2M	2000mm	30mm	0.1*180*220
USB3C-HDMI-3M	3000mm	30mm	0.1*180*220
USB3C-HDMI-5M	5000mm	50mm	0.1*200*250

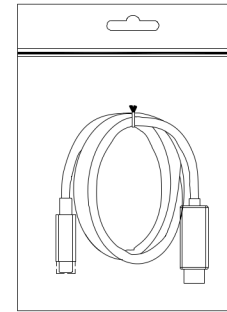

1PCS/QBAG-X(0.10*XXX*XXXmm)+Sticker

Electrical Test:

- 1.Real Test Passed 3840 * 2160P 60Hz.
- 2.Real Test Not Twinkling,Double Vision and Decolor.

NUMBER	PRODUCT SPECIFICATIONS	Quantity	Unit
6	BLACK 45P PVC		G
5	HDMI MALE SHELL(BLACK ABS)	1	PCS
4	USB Type-C MALE SHELL(BLACK ABS)	1	PCS
3	HDMI 19P MALE(Black Insulator,Gold Plated)+PCB*A	1	PCS
2	USB Type-C MALE(White Insulato,Gold Plated)	1	PCS
1	NON-UL(32#*1P+D+AL/MY)*5+32#*4C+24#*2C+AL+B OD=4.8mm,BLACK TPE JACKET.	1	PCS

D		
C		
B		
VER.A	REVISE	DATE
Item	USB3C-HDMI-XM	
Draw	<i>Hobe</i>	Date: 2017.11.02
Approval		
Maker	F16	
Sample NO.	Drawings of 1 (1) Proportion: 1:1 Unit(mm)	