

00 21 36

Tool Case "Robust34" Electric 26 parts




- Fit to fly case, made from impact-resistant polypropylene
- Dustproof and watertight
- Air pressure compensation valve
- Temperatures ranging from - 30°C to + 80° C
- Padlock eyelets
- Document compartment; tool boards with 42 tool pockets and 67 straps
- Lockable base tray can be individually divided using aluminium separator system
- Ergonomic dual-component handle
- Volume: 34 l
- Load-bearing capacity up to 25 kg
- Equipped with 26 brand name tools; some VDE tested in accordance with DIN EN/IEC 60900

Article No.	00 21 36
EAN	4003773082583
Dimension exterior (interior) width mm	510 (480)
Dimension exterior (interior) height mm	215 (199)
Dimension exterior (interior) depth mm	419 (356)
Net weight g	10000



With pressure valve for venting and name plate

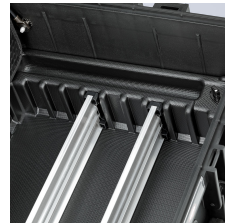

Aluminium separators for individually dividing up the base tray



With document compartment

technical change and errors excepted

Content 00 21 36 (11)

Article No.			Quantity	Nominal size	
00 11 01	Knipex	KNIPEX TwinKey®, for all standard cabinets and shut-off systems	1		
08 26 145	Knipex	Needle-Nose Combination Pliers	1		1000 V
12 40 200	Knipex	Self-Adjusting Insulation Stripper	1	200 mm	
13 86 200	Knipex	Pliers for Electrical Installation	1		1000 V
16 95 01 SB	Knipex	KNIPEX ErgoStrip®, Universal Stripping Tool	1		
70 06 160	Knipex	Diagonal Cutter	1	160 mm	1000 V
87 01 180	Knipex	KNIPEX Cobra®, Hightech Water Pump Pliers	1	180 mm	
97 53 04	Knipex	Self-Adjusting Crimping Pliers for End Sleeves (ferrules), with lateral access	1		
98 52	Knipex	Cable Knife	1	185 mm	1000 V
003484	Wera	Kraftform Kompakt VDE 16 Slim	1		
16135	Stabila	Model 70 Electric spirit level	1	430 mm	