



SNAP-IN ALUMINUM CAPACITORS

4 TERMINAL SNAP-IN DC-LINK SOLUTION

IN A NUTSHELL

LONG LIFETIME

299 PHL-4TSI:
5000 h @ 105 °C

20 years
@ 60 °C

3 000 h
105°C 15 years

10 000 h
85°C 10 years

5 000 h
85°C 5 years


Datasheet Lifetime
vs Application Lifetime

SNAP-IN SOLUTION



299 PHL-4TSI

KEYED
POLARITY
= ONE WAY
MOUNTING

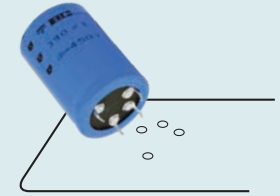


Long life
at high
temperature

Low cost
mounting

High
Ripple
Current

EFFICIENT ASSEMBLY SOLDER ON HIGH CURRENT PC BOARD

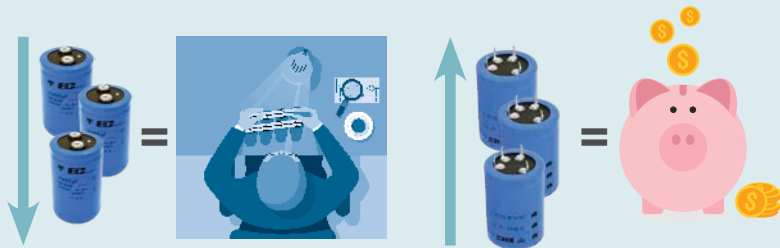

Less Manual Work Saves Time and Cost



Power
Electronics

SIZES BETWEEN SI AND ST



2-Pin SI (mm)
22 x 25
35 x 50



299 PHL-4TSI (mm)
35 x 60
45 x 100



ST (mm)
35 x 80
90 x 220