

# EAO – Your Expert Partner for Human Machine Interfaces

## K14-271.222101 - Illuminated pushbutton

### K14-271.222101 - Illuminated pushbutton



*Attention: The preview is based on a sample product. This can differ from your current configuration.*

#### Mounting

Design	flush
Mounting cut-out	Ø 30,5 mm

#### Front

Front dimension	Ø 35 mm
Front shape	round

#### Other Attributes

Weight	0.031 kg
Operation current	2.5/5 mA ±15 %
Operating voltage	24 V AC/DC

#### Operating-/Indication part

Lens illumination	illuminative
Lens colour	red
Lens material	Plastic
Lens optics	transparent
Lens profile	flush

#### IP-Rating

Front protection	IP67
------------------	------

#### Connection Method

Terminal	Soldering terminal
----------	--------------------

#### Actuator

Switching action	Maintained
Housing colour	black
Housing material	Plastic

#### Switching element

Switching system	Snap-action switching element
Switching current	5 A
Contacts	1 NC + 1 NO
Contact material	
Switching voltage	250 V AC

#### Illumination

LED colour	red
------------	-----


#### Function

Illuminated pushbutton	
------------------------	--


# EAO – Your Expert Partner for Human Machine Interfaces

K14-271.222101 - Illuminated pushbutton


## Dimensions

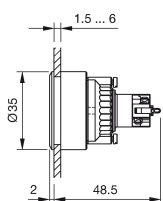

## Mounting cut-outs

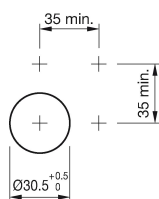

## Wiring diagram

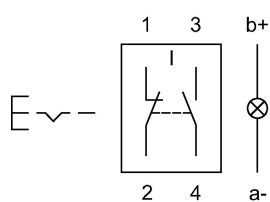

## Legend

Contacts: NC = Normally closed, NO = Normally open