


KEMET, EFX6, Flex Suppressors, Commercial Grade

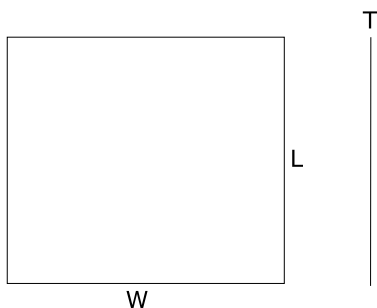

General Information

Series:	EFX6
Style:	Sheet
Description:	Flex Suppressor High Permeability Type
Features:	High Permeability Type
RoHS:	Yes
Qualifications:	UL94 HB, UL File No. E176124
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Dimensions

Sheet Size	240x240mm
L	240mm NOM
W	240mm NOM
T	0.3mm NOM

Specifications

Temperature Range:	-40/+105C
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.8 Atm TYP

Packaging Specifications

Tape Description:	Without PET Tape (Txx00)
Tape Thickness:	0.03mm