


6-Lobe Pin



6-Lobe Pin Screwdriver

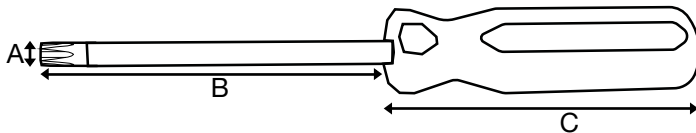

Screwdriver – Dimensions, Weights and Part Numbers

	Part Number	A	B	C	To suit Hafren self tapping Screws	To suit Hafren machine screws	Weight (g)
T10	T10-OPS	10mm	100mm	100mm	No.4 CSK, No.6 BH	M3/M3.5	64g
T15	T15-OPS	15mm	100mm	100mm	No.6 CSK, No.8 BH		64g
T20	T20-OPS	20mm	100mm	100mm	No.8 CSK	M4	64g
T25	T25-OPS	25mm	100mm	100mm	No.10	M5	72g
T30	T30-OPS	30mm	100mm	100mm	No.14	M6	72g
T40	T40-OPS	40mm	100mm	100mm		M8	83g
T45	T45-OPS	45mm	100mm	100mm		M10	100g

* Key Wrenches - Sold in Singles

Material and Finish

Material:


Blade: S2 Steel
Handle: Bi-material soft-grip handles

Heat Treatment: Hardened and tempered

Finish: Self Colour

Packaged: Individually - Polythene grip bag

Polythene Bag Size

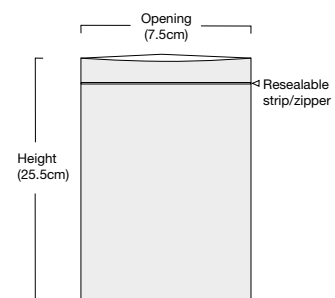

Additional Information

Patented Product: Hafren Fasteners

Installation: 6-Lobe Pin - see video

Removal: 2-Way Removable

- ✓ 6-Lobe drive with internal pin
- ✓ High torque drive
- ✓ Available in multiple heads & threads
- ✓ Stocked in the largest

Every effort has been made to ensure the accuracy of information provided in this datasheet. Hafren Fasteners cannot warrant the information however, expressly or implied, and any liability arising from it is expressly excluded. Customers must satisfy themselves as to the suitability of products and the technical information relating to them, and it is recommended that you conduct your own tests to establish suitability. All sizes shown are in mm without min and max tolerances and are guide sizes. Hafren Fasteners reserve the right to change/alter sizes without notice. This does not effect your statutory rights.