

# 6-Lobe Pin



## 6-Lobe Pin 'L' Key Wrench



## Key Wrenches – Dimensions and Part Numbers


	Part Number	A	B	C	To suit Hafren self tapping screws	To suit Hafren machine screws	Weight (g)
T10	T10-K	18mm	47mm	4mm	No.4 CSK, No.6 BH	M3/M3.5	6g
T15	T15-K	18mm	57mm	4mm	No.6 CSK, No.8 BH		6g
T20	T20-K	22mm	68mm	6mm	No.8 CSK	M4	19g
T25	T25-K	22mm	68mm	6mm	No.10	M5	19g
T27	T27-K	22mm	68mm	6mm	No.12		19g
T30	T30-K	22mm	68mm	6mm	No.14	M6	19g
T40	T40-K	27mm	78mm	8mm		M8	38g
T45	T45-K	27mm	78mm	8mm		M10	38g

\* Key Wrenches - Sold in Singles

## Material and Finish

**Material:** CR-V Steel  
**Heat Treatment:** Hardened HRC 50 -56  
**Finish:** Self Colour

## Polythene Bag Size

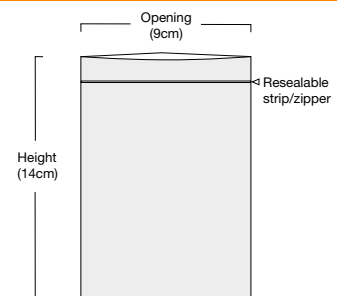

## Additional Information

**Patented Product:** Hafren Fasteners

**Installation:** 6-Lobe Pin Insert Bit - see video

**Removal:** 2-Way Removable



Every effort has been made to ensure the accuracy of information provided in this datasheet. Hafren Fasteners cannot warrant the information however, expressly or implied, and any liability arising from it is expressly excluded. Customers must satisfy themselves as to the suitability of products and the technical information relating to them, and it is recommended that you conduct your own tests to establish suitability. All sizes shown are in mm without min and max tolerances and are guide sizes. Hafren Fasteners reserve the right to change/alter sizes without notice. This does not effect your statutory rights.