




Produktname | *Product name*: Car Charger 9.6A – 4x USB  
 Artikelnummer | *Part Number*: 1000-0017  
 Anfragenummer | *Inquiry Number*: AN-MM-2016-79  
 Ersteller / Datum | *Creator / Date*: DE / 17.02.2017


Version	Change	Date	Name
V0	---	17.02.2017	DE

Template name: USB-cable , Template version: V0

### KFZ Adapter / Car adapter

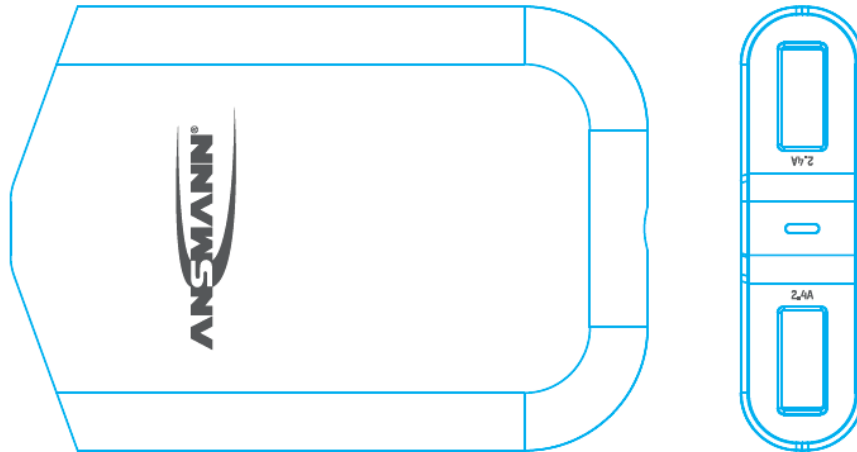

Date Code (coded production date)

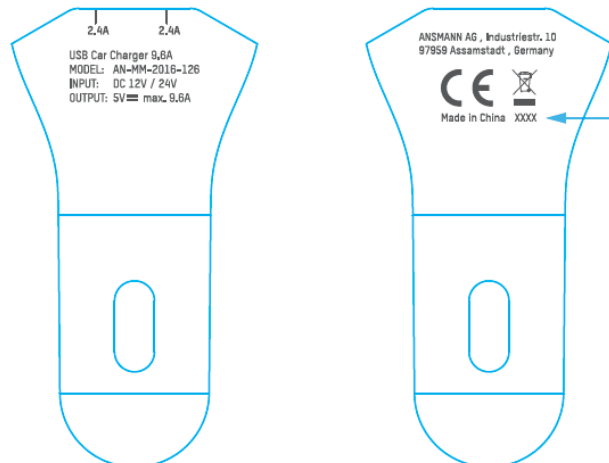

Allowable deviation / general tolerances DIN ISO 2768-c

**Technische Daten / technical data:**



Eingangsdaten	12-24V DC max. 5000mA	<i>input data</i>	12-24V DC max. 5000mA
Ausgangsspannung	5V DC $\pm 5\%$	<i>Output voltage</i>	5V DC $\pm 5\%$
Ladestrom	max. 9600mA (4x max. 2400mA)	<i>Charge current</i>	max. 9600mA (4x max. 2400mA)
Leistung	max. 48W (4x max. 12W)	<i>Power</i>	max. 48W (4x max. 12W)
Anschluss	4x USB Port (2x Stecker 2x Verlängerung)	<i>Connector</i>	4x USB Port (2x connector 2x extension)
USB Beschaltung	Smart IC	<i>USB Resistor network</i>	Smart IC
Anzeige LED	Blau	<i>Indicator LED</i>	<i>Blue</i>
Stecker Sicherung	Ja	<i>Plug Fuse</i>	Yes
Überstromschutz	Ja / 3500mA $\pm 100$ mA	<i>Over-current protection</i>	Yes / 3500mA $\pm 100$ mA
Kurzschlusserkennung	Ja	<i>Short circuit detection</i>	Yes
Kabel	180cm $\pm 10$ cm	<i>Cable</i>	180cm $\pm 10$ cm
Zubehör	Clip an der Verlängerung	<i>Equipment</i>	Clip at the Extension
Approbation	CE	<i>approval</i>	CE
Gehäuse	KFZ-Steckergehäuse, schwarz	<i>case</i>	car lighter plug-in case,black
Betriebstemperatur	0°C.....+25°C	<i>operating temperature</i>	0°C.....+25°C
Lagertemperatur	-25°C.....+70°C	<i>storage temperature</i>	-25°C.....+70°C
Gewicht	131g	<i>weight</i>	131g