


## LED Spotlights

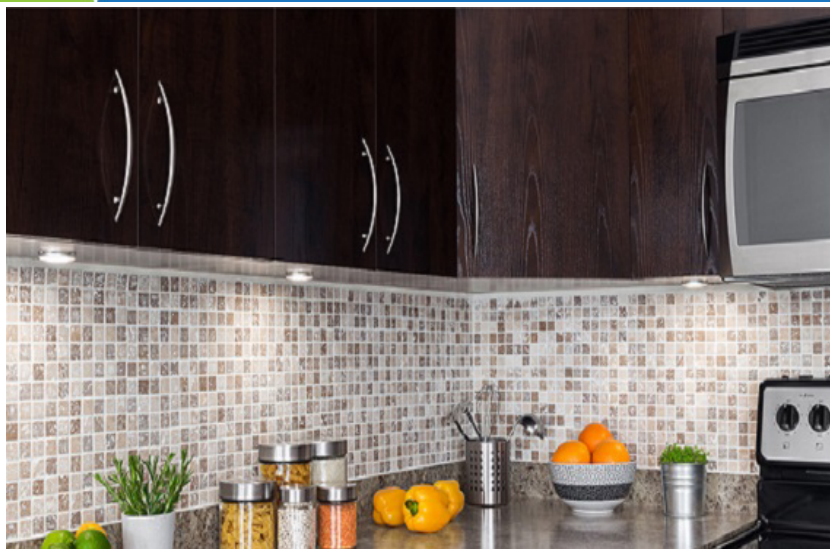

### VT-227D

#### HIGHLIGHTS :

WATTS



6.5

EQ. WATTS



55

LUMINOUS



450

BEAM ANGLE



38

#### PRODUCT FEATURES

|                            |                    |
|----------------------------|--------------------|
| Item No                    | : VT-227D          |
| SKU Code                   | : 195              |
| Watts                      | : 6.5              |
| EQ. Watts                  | : 55               |
| Base / holder              | : GU10             |
| Voltage                    | : AC:220-240V,50Hz |
| Lumen(lm)                  | : 450              |
| Color Temperature          | : 3000K            |
| Beam Angle                 | : 38               |
| PF                         | : >0.5             |
| LED Chip Type              | : SMD-Samsung Chip |
| CRI                        | : >80              |
| Energy rating label        | : A+               |
| IP Rating Protection Class | : IP20             |
| Body type                  | : Plastic          |
| Dimmable                   | : Yes              |
| Life Time                  | : 30,000 Hours     |
| EAN code                   | : 3800157631600    |
| Unit size                  | : ø50x55mm         |
| Packing details            | : 200.00           |